



BNC Coaxial Connectors Series-B

1. BNC Straight Plug (Flexible Cable-Clamp Attachment)

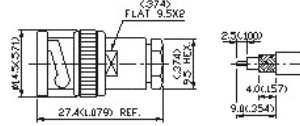


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0704B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50PAN0704BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50PAN0704D1X	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0704DCX	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0711B1X	RG 59,62A,210	Center Contact: gold plated	Delrin
BNC-50PAN0711BRX	RG 59,62A,210	Center Contact: gold plated	Teflon
BNC-50PAN0711D1X	RG 59,62A,210	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0711DCX	RG 59,62A,210	Center Contact: gold plated Coupling Nut: Diecast	Teflon

2. BNC Straight Plug (Flexible Cable-Clamp Attachment)

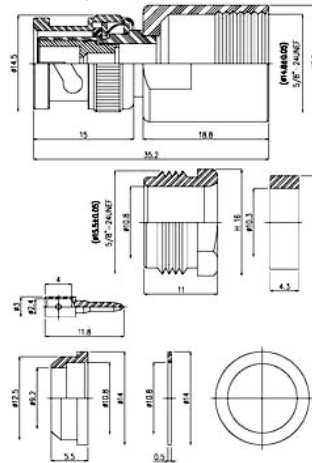


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0719B1X	RG 8A, 213	Center Contact: gold plated	Delrin
BNC-50PAN0719BRX	RG 8A, 213	Center Contact: gold plated	Teflon
BNC-50PAN0719D1X	RG 8A, 213	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0719DCX	RG 8A, 213	Center Contact: gold plated Coupling Nut: Diecast	Teflon

3. BNC Straight Jack (Flexible Cable-Clamp Attachment)

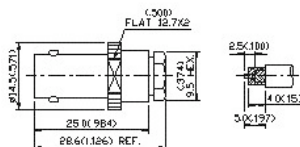


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN0704B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50SAN0704BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50SAN0711B1X	RG 59,62A,210	Center Contact: gold plated	Delrin
BNC-50SAN0711BRX	RG 59,62A,210	Center Contact: gold plated	Teflon

4. BNC Straight Square Flange Jack (Flexible Cable-Clamp Attachment)

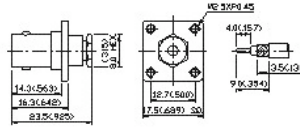


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN8002BRX	RG 174, 188A, 316	Center Contact: gold plated	Teflon

5. BNC Straight Plug Crimp (Flexible Cable-Crimp Attachment)

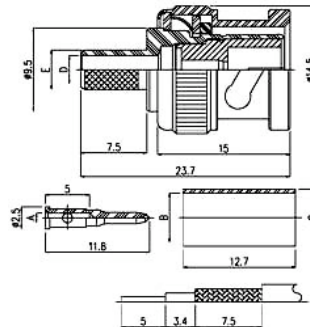


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0204B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50PAN0204BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50PAN0204D1X	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0204DCX	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0211B1X	RG 59, 62A, 210	Center Contact: gold plated	Delrin
BNC-50PAN0211BRX	RG 59, 62A, 210	Center Contact: gold plated	Teflon
BNC-50PAN0211D1X	RG 59, 62A, 210	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0211DCX	RG 59, 62A, 210	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0202AAX	RG 174, 188A, 316, step-down ferrule	Center Contact: gold plated	Teflon
BNC-50PAN0202A1X	RG 174, 188A, 316, step-down ferrule	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-75PAN0206BRX	RG 179B, 187A, 75Ω	Center Contact: gold plated	Teflon
BNC-75PAN0206DCX	RG 179B, 187A, 75Ω	Center Contact: gold plated Coupling Nut: Diecast	Teflon

6. BNC Straight Plug Crimp (Flexible Cable-Crimp Attachment)

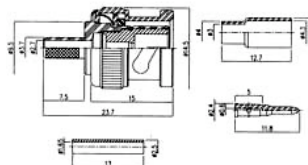


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0202B1X	RG 174, 188A, 316	Center Contact: gold plated	Delrin
BNC-50PAN0202BRX	RG 174, 188A, 316	Center Contact: gold plated	Teflon
BNC-50PAN0202D1X	RG 174, 188A, 316	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0202DCX	RG 174, 188A, 316	Center Contact: gold plated Coupling Nut: Diecast	Teflon

7. BNC Y Type Plug Crimp (Flexible Cable-Crimp Attachment)

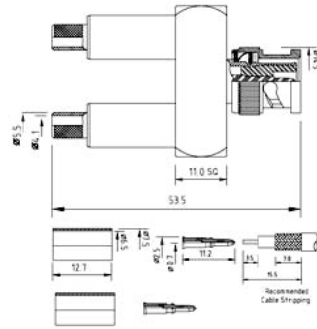


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0904BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50PAN0904DCX	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0911BRX	RG 59, 62A, 210	Center Contact: gold plated	Teflon
BNC-50PAN0911DCX	RG 59, 62A, 210	Center Contact: gold plated Coupling Nut: Diecast	Teflon

8. BNC Right Angle Plug Crimp (Flexible Cable-Crimp Attachment)

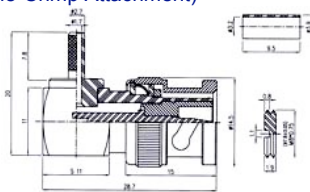

Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0404B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50PAN0404BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50PAN0404D1X	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0404DCX	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0411B1X	RG 59, 62A, 210 (solder contact)	Center Contact: gold plated	Delrin
BNC-50PAN0411BRX	RG 59, 62A, 210 (solder contact)	Center Contact: gold plated	Teflon
BNC-50PAN0411D1X	RG 59, 62A, 210 (solder contact)	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN0411DCX	RG 59, 62A, 210 (solder contact)	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0402BRX	RG 174, 188A, 316 (solder contact)	Center Contact: gold plated	Teflon
BNC-50PAN0402DCX	RG 174, 188A, 316 (solder contact)	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-75PAN0406BRX	RG 179B, 187A (solder contact)	Center Contact: gold plated	Teflon
BNC-75PAN0406DCX	RG 179B, 187A (solder contact)	Center Contact: gold plated Coupling Nut: Diecast	Teflon


9. BNC Right Angle Plug Crimp (Flexible Cable-Crimp Attachment)

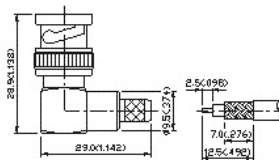

Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN0504BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50PAN0504DCX	RG 58,58A,141A	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0511BRX	RG 59, 62A, 210	Center Contact: gold plated	Teflon
BNC-50PAN0511DCX	RG 59, 62A, 210	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-50PAN0502BRX	RG 174, 188A, 316 (step-down ferrule)	Center Contact: gold plated	Teflon
BNC-50PAN0502DCX	RG 174, 188A, 316 (step-down ferrule)	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-75PAN0506BRX	RG 179B, 187A, 75Ω	Center Contact: gold plated	Teflon


BNC-75PAN0506DCX	RG 179B, 187A, 75Ω	Center Contact: gold plated Coupling Nut: Diecast	Teflon
------------------	--------------------	--	--------

10. BNC Straight Bulkhead Jack Crimp (Flexible Cable-Crimp Attachment)

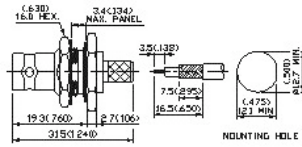


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN6404B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50SAN6404BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50SAN6411B1X	RG 59, 62A, 210	Center Contact: gold plated	Delrin
BNC-50SAN6411BRX	RG 59, 62A, 210	Center Contact: gold plated	Teflon

11. BNC Straight Bulkhead Jack Crimp (Flexible Cable-Crimp Attachment)

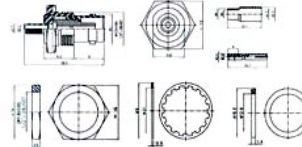


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN6402BRX	RG 174, 188A, 316 (step-down ferrule)	Center Contact: gold plated	Teflon
BNC-75SAN6406BRX	RG 179B, 187A, 75Ω	Center Contact: gold plated	Teflon

12. BNC Straight Jack Crimp (Flexible Cable-Crimp Attachment)

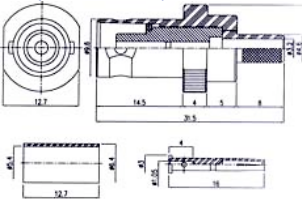


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN0204B1X	RG 58,58A,141A	Center Contact: gold plated	Delrin
BNC-50SAN0204BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50SAN0211B1X	RG 59, 62A, 210	Center Contact: gold plated	Delrin
BNC-50SAN0211BRX	RG 59, 62A, 210	Center Contact: gold plated	Teflon

13. BNC Straight Jack Crimp (Flexible Cable-Crimp Attachment)

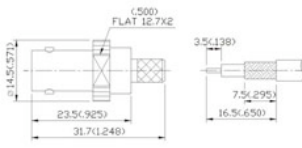


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN0202BRX	RG 174, 188A, 316 (step-down ferrule)	Center Contact: gold plated	Teflon
BNC-75SAN0206BRX	RG 179B, 187A, 75Ω	Center Contact: gold plated	Teflon

14. BNC Straight Bulkhead Jack Crimp (Flexible Cable-Crimp Attachment)

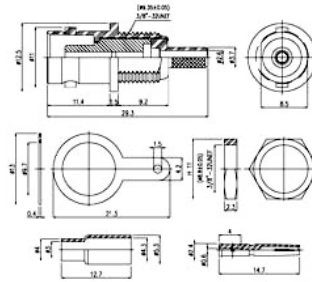


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN7304BRX	RG 58,58A,141A	Center Contact: gold plated	Teflon
BNC-50SAN7302BRX	RG 174, 188A, 316 (step-down ferrule)	Center Contact: gold plated	Teflon

15. BNC Straight Bulkhead Jack Crimp (Flexible Cable-Crimp Attachment)

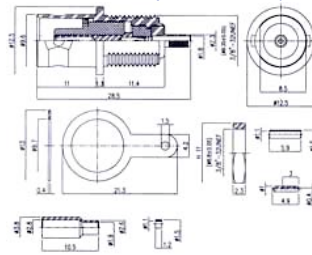


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN7301BRX	RG 178, 196	Center Contact: gold plated	Teflon

16. BNC Straight Plug Twist-on (Flexible Cable Twist-on Attachment)

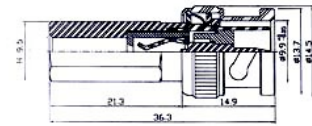


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN1004B1X	RG 58, 58A, 141A	Center Contact: gold plated	Delrin
BNC-50PAN1004D1X	RG 58, 58A, 141A	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN1011B1X	RG 59, 62A, 210	Center Contact: gold plated	Delrin
BNC-50PAN1011D1X	RG 59, 62A, 210	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-75PAN1011D1X	RG 59U	Center Contact: gold plated	Delrin

 17. BNC Straight Jack Twist-on (Flexible Cable Twist-on Attachment)




Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50SAN1004B1X	RG 58, 58A, 141A	Center Contact: gold plated	Delrin
BNC-50SAN1011B1X	RG 59, 62A, 210	Center Contact: gold plated	Delrin

18. BNC Straight Plug For Molded Type (Flexible Cable Molded Type)

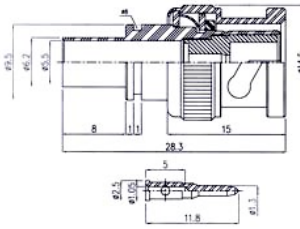


Ordering Code	Applicable Cable RG/U	Finish	Insulation
BNC-50PAN1104B1X	RG 58, 58A, 141A	Center Contact: gold plated	Delrin
BNC-50PAN1104BRX	RG 58, 58A, 141A	Center Contact: gold plated	Teflon

19. BNC Straight PCB Mount Jack Receptacle (Printed Circuit Board Receptacle)

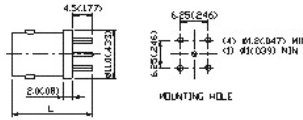


Ordering Code	Profile Detail	Finish	Insulation
BNC-50SAN7050BRX	L=18.2mm	Center Contact: gold plated	Teflon
BNC-75SAN7050BRX	L=18.2mm, 75Ω	Center Contact: gold plated	Teflon
BNC-50SAN7051B1X	L=23.2mm	Center Contact: gold plated	Delrin
BNC-75SAN7051B1X	L=23.2mm, 75Ω	Center Contact: gold plated	Delrin
BNC-50SAN7051BRX	L=23.2mm	Center Contact: gold plated	Teflon
BNC-75SAN7051BRX	L=23.2mm, 75Ω	Center Contact: gold plated	Teflon
BNC-75SAN7052B1X	L=25.2mm, 75Ω	Center Contact: gold plated	Delrin
BNC-75SAN7052BRX	L=25.2mm, 75Ω	Center Contact: gold plated	Teflon
BNC-50SAN7053BRX	L=32.1mm	Center Contact: gold plated	Teflon
BNC-75SAN7053BRX	L=32.1mm, 75Ω	Center Contact: gold plated	Teflon

20. BNC Straight PCB Mount Jack Receptacle (Printed Circuit Board Receptacle)

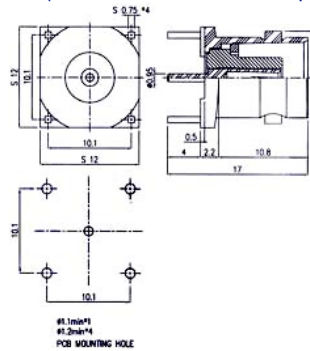


Ordering Code	Profile Detail	Finish	Insulation
BNC-50SAN7154BRX	L=17.0mm	Center Contact: gold plated	Teflon
BNC-75SAN7154BRX	L=17.0mm, 75Ω	Center Contact: gold plated	Teflon
BNC-50SAN7155BRX	L=27.5mm	Center Contact: gold plated	Teflon
BNC-75SAN7155BRX	L=27.5mm, 75Ω	Center Contact: gold plated	Teflon
BNC-75SAN7156BRX	L=22.7mm, 75Ω	Center Contact: gold plated	Teflon
BNC-75SAN7157BRX	L=26.0mm, 75Ω	Center Contact: gold plated	Teflon

21. BNC Right Angle PCB Mount Jack Receptacle (PCB Receptacle)

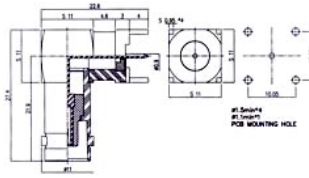


Ordering Code	Profile Detail	Finish	Insulation
BNC-50SAN7559BRX	L=22.4mm	Center Contact: gold plated	Delrin
BNC-50SAN7560BRX	L=27.4mm	Center Contact: gold plated	Delrin

 22. BNC Straight PCB Mount Jack Receptacle (PCB Receptacle)



Ordering Code	Finish	Insulation
BNC-50SAN5163D1X	Center Contact: gold plated Body: Diecast	Delrin

 23. BNC Right Angle PCB Mount Jack Receptacle (PCB Receptacle)




Ordering Code	Profile Detail	Finish	Insulation
BNC-50SAN7561D1X	High Profile H=15.6mm	Center Contact: gold plated Body: Diecast	Delrin
BNC-50SAN7562D1X	Low Profile H=13.1mm	Center Contact: gold plated Body: Diecast	Delrin

24. BNC Right Angle PCB Mount Jack Receptacle (PCB Receptacle)




Ordering Code	Profile Detail	Finish	Insulation
BNC-50SAN7564D1X	High Profile H=15.6mm	Center Contact: gold plated Body&Housing: Diecast	Delrin
BNC-50SAN7565D1X	Low Profile H=13.1mm	Center Contact: gold plated Body&Housing: Diecast	Delrin

25. BNC Straight Bulkhead Plug Receptacle (Bulkhead/Panel Mount Receptacle)

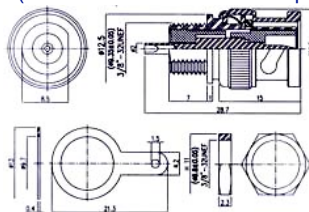


Ordering Code	Finish	Insulation
BNC-50PAN7366B1X	Center Contact: gold plated	Delrin
BNC-50PAN7366BRX	Center Contact: gold plated	Teflon
BNC-50PAN7366D1X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50PAN7366DCX	Center Contact: gold plated Coupling Nut: Diecast	Teflon

26. BNC Straight Bulkhead Jack Receptacle (Bulkhead/Panel Mount Receptacle)

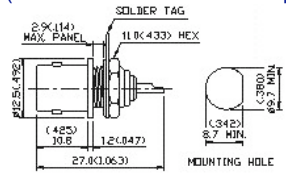


Ordering Code	Finish	Insulation
BNC-50SAN7366B1X	Center Contact: gold plated	Delrin
BNC-75SAN7366B1X	Center Contact: gold plated	Delrin
BNC-50SAN7366BRX	Center Contact: gold plated	Teflon
BNC-75SAN7366BRX	Center Contact: gold plated	Teflon
BNC-50SAN7366D1X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-75SAN7366D1X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNC-50SAN7366DCX	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNC-75SAN7366DCX	Center Contact: gold plated Coupling Nut: Diecast	Teflon

27. BNC Isolated Bulkhead Jack Receptacle (Bulkhead/Panel Mount Receptacle)

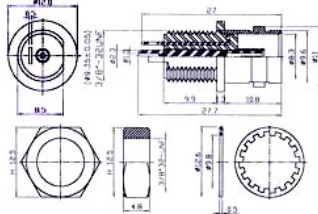


Ordering Code	Finish	Insulation
BNC-50SAN7367B2X	Center Contact: gold plated	ABS
BNC-75SAN7367B2X	Center Contact: gold plated	ABS

28. BNC Square Flange Jack Receptacle (Bulkhead/Panel Mount Receptacle)

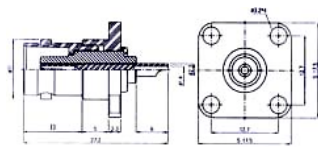


Ordering Code	Finish	Insulation
BNC-50SAN5268BRX	Center Contact: gold plated	Teflon

29. BNC Bulkhead Jack-Jack (In-Series Adapters)

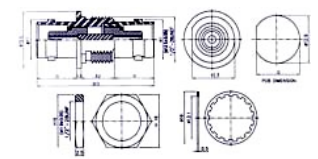


Ordering Code	Finish	Insulation
BNCS-BNCSAN03X	Center Contact: gold plated	Delrin
BNCS-BNCSAN03X75	Center Contact: gold plated	Delrin
BNCS-BNCSAN02X	Center Contact: gold plated	Teflon
BNCS-BNCSAN02X 75	Center Contact: gold plated	Teflon

30. BNC Isolated Bulkhead Jack-Jack (In-Series Adapters)

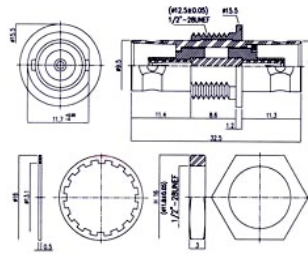


Ordering Code	Finish	Insulation
BNCS-BNCSAN04X	Center Contact: gold plated	Delrin
BNCS-BNCSAN04X75	Center Contact: gold plated	Delrin
BNCS-BNCSAN05X	Center Contact: gold plated	Teflon
BNCS-BNCSAN05X75	Center Contact: gold plated	Teflon

31. BNC Plug-Plug (In-Series Adapters)

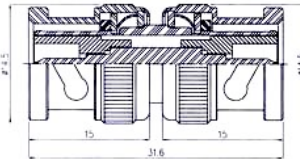


Ordering Code	Finish	Insulation
BNCP-BNCPAN06X	Center Contact: gold plated	Delrin
BNCP-BNCPAN06X75	Center Contact: gold plated	Delrin
BNCP-BNCPAN01X	Center Contact: gold plated	Teflon
BNCP-BNCPAN01X75	Center Contact: gold plated	Teflon
BNCP-BNCPAN07X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNCP-BNCPAN07X75	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNCP-BNCPAN08X	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNCP-BNCPAN08X75	Center Contact: gold plated Coupling Nut: Diecast	Teflon

32. BNC Jack-Jack (In-Series Adapters)

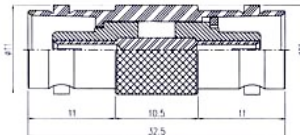


Ordering Code	Finish	Insulation
BNCS-BNCSAN06X	Center Contact: gold plated	Delrin
BNCS-BNCSAN06X75	Center Contact: gold plated	Delrin
BNCS-BNCSAN01X	Center Contact: gold plated	Teflon
BNCS-BNCSAN01X75	Center Contact: gold plated	Teflon
BNCS-BNCSAN07X	Center Contact: gold plated Coupling Nut: Diecast	Delrin

33. BNC Right Angle Plug-Jack (In-Series Adapters)

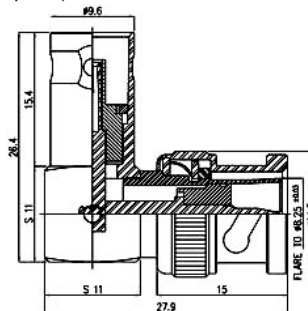


Ordering Code	Finish	Insulation
BNCP-BNCSAN21X	Center Contact: gold plated	Delrin
BNCP-BNCSAN21X75	Center Contact: gold plated	Delrin
BNCP-BNCSAN20X	Center Contact: gold plated	Teflon
BNCP-BNCSAN20X75	Center Contact: gold plated	Teflon
BNCP-BNCSAN22X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNCP-BNCSAN22X75	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNCP-BNCSAN23X	Center Contact: gold plated Coupling Nut: Diecast	Teflon
BNCP-BNCSAN23X75	Center Contact: gold plated Coupling Nut: Diecast	Teflon

34. BNC Tee Adapter Jack-Jack-Jack (In-Series Adapters)

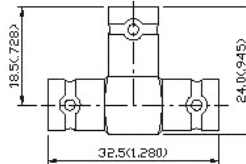


Ordering Code	Finish	Insulation
BNCS-BNCSAN30X	Center Contact: gold plated	Delrin
BNCS-BNCSAN31X	Center Contact: gold plated	Teflon

35. BNC Right Angle Adapter Jack-Plug-Jack (In-Series Adapters)

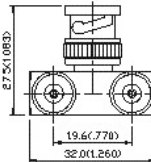


Ordering Code	Finish	Insulation
BNCP-BNCSAN32X	Center Contact: gold plated	PP

36. BNC Tee Adapter Jack-Plug-Jack (In-Series Adapters)

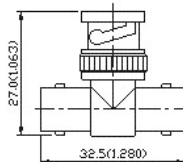


Ordering Code	Finish	Insulation
BNCP-BNCSAN30X	Center Contact: gold plated	Delrin
BNCP-BNCSAN31X	Center Contact: gold plated	Teflon
BNCP-BNCSAN33X	Center Contact: gold plated Coupling Nut: Diecast	Delrin
BNCP-BNCSAN34X	Center Contact: gold plated Coupling Nut: Diecast	Teflon

37. BNC Tee Adapter Jack-Plug-Jack (In-Series Adapters)

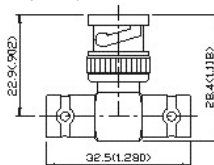


Ordering Code	Finish	Insulation
BNCP-BNCSAN35X	Center Contact: gold plated Coupling Nut: Diecast	Delrin

38. BNC Y Adapter Jack-Plug-Jack (In-Series Adapters)

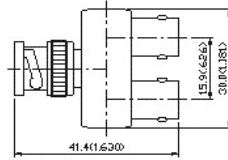


Ordering Code	Finish	Insulation
BNCP-BNCSAN40X	Center Contact: gold plated	Teflon

39. BNC 75 Ohm Straight Bulkhead Jack Insulated (PCB Mount)

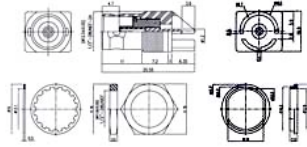



Ordering Code	Finish	Insulation
BNC-75SAG7776BRX	Center Contact and Housing: gold plated Insulation: Teflon	Teflon

40. BNC 75 Ohm Straight Bulkhead Jack (PCB Mount)

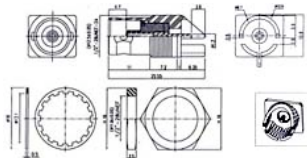

Ordering Code	Finish	Insulation
BNC-75SAG7775BRX	Center Contact and Housing: gold plated Insulation: Teflon	Teflon

41. BNC Straight Bulkhead Jack receptacle with solder cup and O-Ring seal

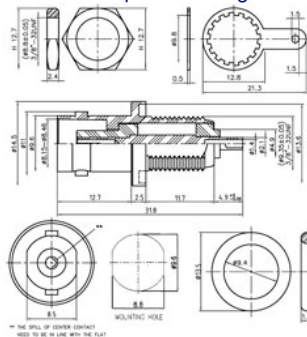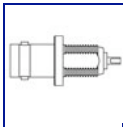

Ordering Code	Finish	Insulation
BNC-50SAN7383BRX	Center Contact: gold plated Housing: nickel plated Insulation: Teflon	Teflon

For other plating options contact factory

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[BNC-50PAN0204BRX](#)