

“Stay Connected” with



Solar Power Components

a PennEngineering® Company


Heyco® Quarter-Turn Mount Wire Clips SBCQTM Series

**ALL NEW
PRODUCT!**




| BUNDLE DIAMETER | | | | PART NO. | | DESCRIPTION | PART DIMENSION | | | | | | |
|-----------------------------------|------|-------------------------------|------|-------------|------------|--------------|----------------|------|------|------|-----|-----|-----|
| HS Nylon 6/6 Black 100 Pack | | HS Nylon 6/6 Black Bulk | | A Height | B Width | | C Depth | | | | | | |
| in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. |
| .29 | 7,4 | .44 | 11,2 | 15412B | 15414B | SBCQTM-3 437 | 1.03 | 26,2 | 1.12 | 28,4 | | | |
| .41 | 10,4 | .69 | 17,5 | 15416B | 15418B | SBCQTM-3 687 | 1.18 | 30,0 | 1.24 | 31,5 | .31 | 7,9 | |
| .60 | 15,2 | .88 | 22,2 | 15420B | 15422B | SBCQTM-3 875 | 1.51 | 38,4 | 1.66 | 42,2 | | | |
| .29 | 7,4 | .44 | 11,2 | 15348B | 15350B | SBCQTM-2 437 | 1.03 | 26,2 | 1.12 | 28,4 | | | |
| .41 | 10,4 | .69 | 17,5 | 15352B | 15354B | SBCQTM-2 687 | 1.18 | 30,0 | 1.24 | 31,5 | .31 | 7,9 | |
| .60 | 15,2 | .88 | 22,2 | 15356B | 15358B | SBCQTM-2 875 | 1.51 | 38,4 | 1.66 | 42,2 | | | |
| .29 | 7,4 | .44 | 11,2 | 15484B | 15486B | SBCQTM-5 437 | 1.03 | 26,2 | 1.12 | 28,4 | | | |
| .41 | 10,4 | .69 | 17,5 | 15488B | 15490B | SBCQTM-5 687 | 1.18 | 30,0 | 1.24 | 31,5 | .31 | 7,9 | |
| .60 | 15,2 | .88 | 22,2 | 15492B | 15494B | SBCQTM-5 875 | 1.51 | 38,4 | 1.66 | 42,2 | | | |

- Simple application by hand with quick twist 90° swivel for friction fit, hold in place with high pull-out retention.
- Simply twist to remove for routing and location adjustment.
- Wide cable diameter range handles multiple applications.
- Releasable and reusable.
- Secure clamping will not release easily.
- Locking feature prevents twisting apart.
- **All new Quarter-Turn Mount #3 style (QTM-3)**, designed to work with popular IronRidge and Unirac solar racking systems.
- Could be used in any 3/8" T-Slot racking or rail system from other manufacturers.
- **All new Quarter-Turn Mount #2 style (QTM-2)**, designed to work with popular IronRidge and Unirac and Small Solar Stack solar racking systems.
- QTM-2 could be used in any 1/4" T-Slot racking or rail system from other manufacturers.
- **All new Quarter-Turn Mount #5 style (QTM-5)**, designed to work with popular large Solar Stack racking systems.
- QTM-5 can also be used on Powermation racking for industrial automation and robotics workstations.
- QTM-5 could be used in any 1/2" T-Slot racking or rail system from other manufacturers.

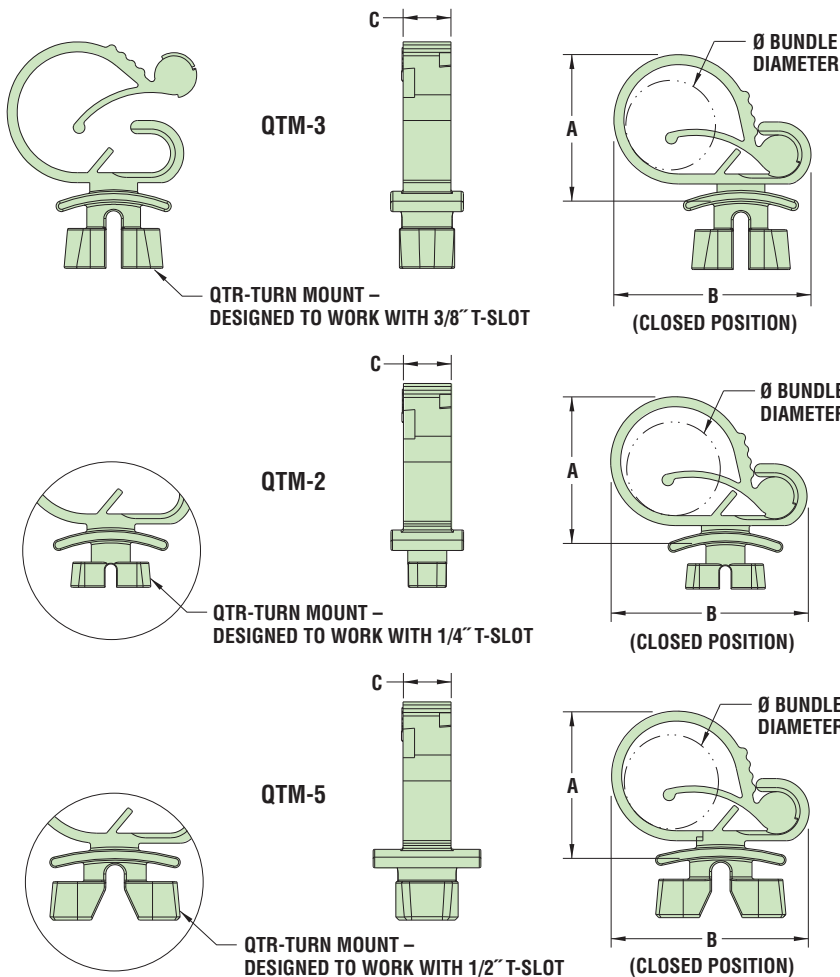

Material: Nylon 6/6, Heat Stable / UV Stable
 Flammability Rating: UL 94 V-2
 Temperature Range: -40°F (-40°C) to 239°F (115°C)

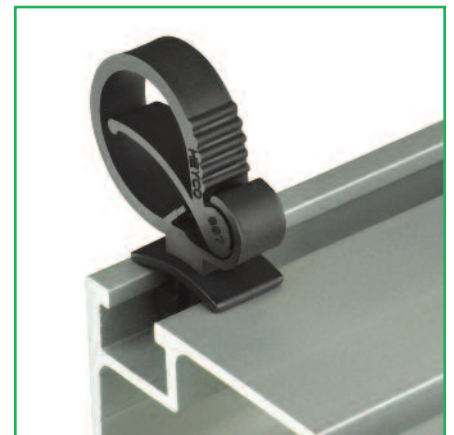

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[15350B](#) [15484B](#) [15488B](#) [15416B](#) [15348B](#) [15414B](#) [15492B](#) [15354B](#) [15412B](#) [15352B](#) [15356B](#) [15420B](#) [15422B](#)
[15418B](#) [15358B](#)