

"Stay Connected" with




Liquid Tight Cordgrips

a PennEngineering® Company

Heyco® -Tite Tear-Away Liquid Tight Cordgrips


Straight-Thru, Metric Hubs with Integral Sealing Ring

The Ultimate in Liquid Tight Strain Relief Protection


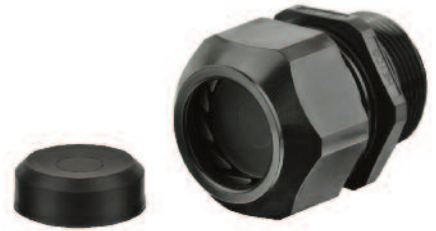


Cable Diameter Range				Part No.				Description	Part Dimensions									
Minimum		Maximum		Including Nylon Nut*		No Nut			A Clearance Hole Dia.		B Max. O.A. Length		C Thread Length		D Wrenching Nut Thickness		E Flat Size	
in.	mm.	in.	mm.	Black	Gray	Black	Gray		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
Metric Hubs																		
.170	4,3	.450	11,4	M4340-SM	M4341-SM	M4372-SM	M4373-SM	SMCG M20	.787	20,0	1.53	38,9	.41	10,4	.21	5,3	.98	24,9
.260	6,6	.545	13,8	M3198-SM	M3199-SM	M4360-SM	M4361-SM	SMCG LL M20	.787	20,0	1.65	41,9	.43	10,9	.25	6,4	1.06	26,9
.435	11,0	.706	17,9	M4344-SM	M4345-SM	M4376-SM	M4377-SM	SMCG M25	.985	25,0	1.89	48,0	.52	13,2	.25	6,4	1.30	33,0
.590	15,0	1.000	25,4	M4348-SM	M4349-SM	M4380-SM	M4381-SM	SMCG M32	1.260	32,0	2.23	56,6	.57	14,5	.30	7,6	1.73	43,9
.865	22,0	1.260	32,0	M4352-SM	M4353-SM	M4384-SM	M4385-SM	SMCG M40	1.575	40,0	2.39	60,7	.47	11,9	.30	7,6	2.05	52,1
1.230	31,2	1.560	39,6	M3300-SM	M3301-SM	-	-	SMCG M50	1.970	50,0	2.50	63,5	.48	12,2	.36	9,1	2.46	62,5
1.450	36,8	1.730	43,9	M3304-SM	M3305-SM	-	-	SMCG M63	2.480	63,0	2.63	66,8	.50	12,7	.42	10,7	2.73	69,3


*Nylon locknuts shipped unassembled.

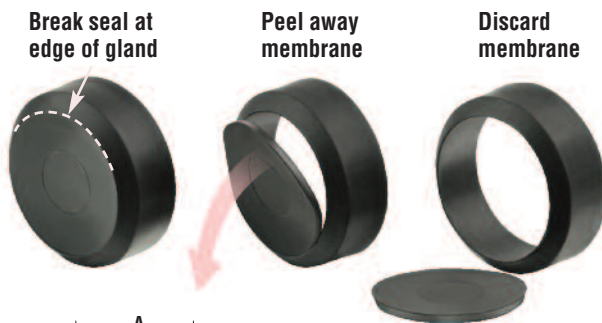

Click here or scan for assembly instructions

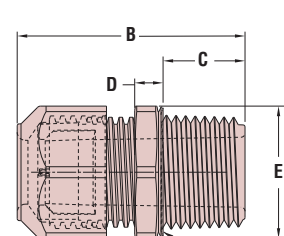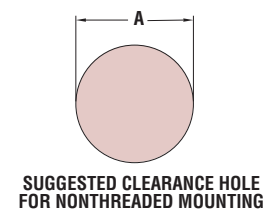

INTEGRAL SEALING RING

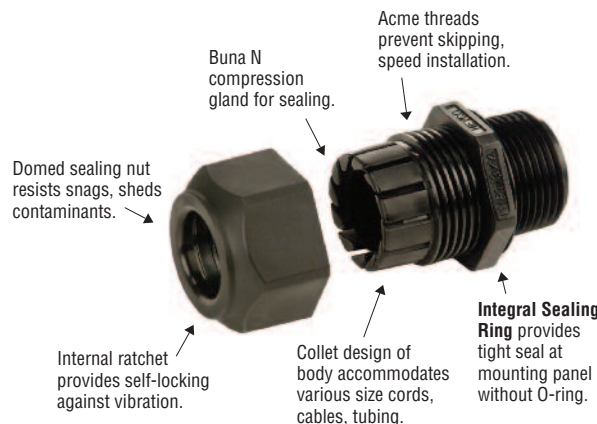

- The **New Tear-Away** Liquid Tight Cordgrips install as a plug to keep rain, insects and air contaminants outside of an enclosure that is waiting at field installation sites or even within a manufacturing setting for a prolonged period of time.
- **Note:** UL Certifications apply only when used as a cordgrip, not as a plug; When used as a plug, we meet IPx8 @ 2.6 PSI for 24 hrs, and IPx5.
- Units remain internally clean and moisture free until cable installation as a Heyco standard, and market-leading Cable Gland with full functionality that you have come to expect.
- Simply puncture the gland edge with a flat-head screwdriver and Tear-Away the ID for cable pass through like a standard Heyco Cable Gland.
- **Integral Sealing Ring** ensures a superior seal at the clearance or threaded mounting hole locaton.
- Approved for **NEMA 4, 4X, 6 and 6P applications** with use of nylon locknuts.
- IP 68 rated.
- Cordgrips are made of nylon construction with TPE sealing glands that resist salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents.
- Consult Heyco for Cordgrips molded in other colors.

Material

Nylon 6/6 with TPE Sealing Gland

Certifications
(when used as Cordgrip)



Listed under Underwriters' Laboratories File E51579



Recognized under the Component Program of Underwriters' Laboratories File E51579 to both Canadian and U.S. requirements



Certified by the Canadian Standards Association File 93876

Flammability Rating

94V-2 Standard

Temperature Range

Static -40°F (-40°C) to 239°F (115°C)

Dynamic -4°F (-20°C) to 212°F (100°C)

IP Rating

IP 68 (70 PSI, 5 BAR)

(IPx8 @ 2.6 PSI for 24 hrs and IPx5, when used as plug)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M4360-SM](#) [M4377-SM](#) [M4376-SM](#) [M3305-SM](#) [M3300-SM](#) [M3304-SM](#) [M4361-SM](#) [M4384-SM](#) [M3301-SM](#)
[M4344-SM](#) [M4345-SM](#) [M4349-SM](#) [M4348-SM](#) [M3198-SM](#) [M4352-SM](#) [M4385-SM](#) [M4380-SM](#) [M4381-SM](#) [M4353-](#)
[SM](#) [M3199-SM](#)