
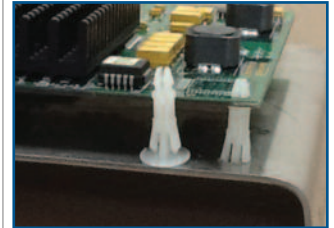


Heyco® Nylon PCB Supports - Metric Reverse Locking

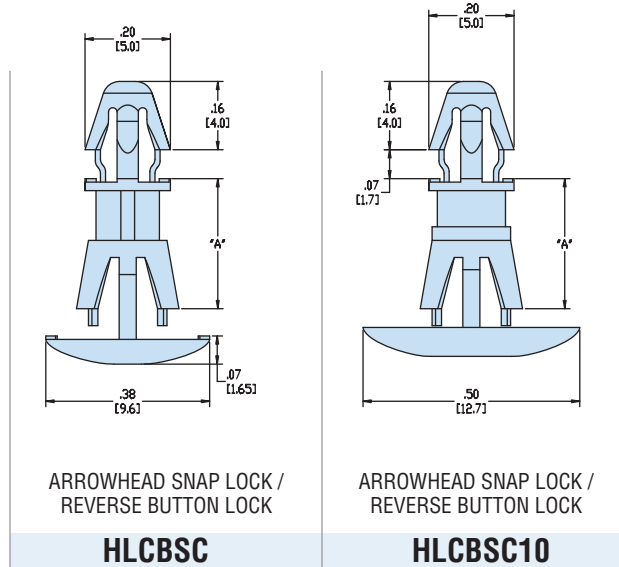

| | Maximum Thickness | | Mounting Hole Diameter | | Maximum Thickness | | Mounting Hole Diameter | |
|----------------|-------------------|-----|------------------------|-----|-------------------|-----|------------------------|-----|
| | in. | mm. | in. | mm. | in. | mm. | in. | mm. |
| PCB | .062 | 1,6 | .157 | 4,0 | .062 | 1,6 | .157 | 4,0 |
| Chassis | .062 | 1,6 | .212 | 5,4 | .062 | 1,6 | .212 | 5,4 |

| A mm. | PART NO. Natural | DESCRIPTION | PART NO. Natural | DESCRIPTION |
|-----------------|----------------------------|--------------------|----------------------------|--------------------|
| 6,0 | 10433 | HLCBSC-06M | | |
| 8,0 | 10434 | HLCBSC-08M | 10439 | HLCBSC10-08M |
| 10,0 | 10435 | HLCBSC-10M | 10440 | HLCBSC10-10M |
| 12,0 | 10436 | HLCBSC-12M | 10441 | HLCBSC10-12M |
| 14,0 | 10437 | HLCBSC-14M | 10442 | HLCBSC10-14M |

Standard color natural. For special order parts in UL 94V-0 material, add the suffix "F" to Part No.

Material: Nylon 6/6
 Flammability Rating: 94V-2
 Temperature Range: -40°F (-40°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10434B](#)