


Heyco® Quarter-Turn Mount Wire Clips Helios QTM-5

WIRE DIAMETER RANGE 1-2 Wires	Nylon 6/6 Natural	PART NO. HS Nylon 6/6 Black	VO Nylon 6/6 Black	DESCRIPTION	PART DIMENSION		
					A Height in. mm.	B Width in. mm.	C Depth in. mm.
.230 (5,8 mm) - .315 (8,0 mm) Each Cable	S6639	S6639B	S6639F	Helios QTM-5	1.03 26,2	.87 22,1	.38 9,6

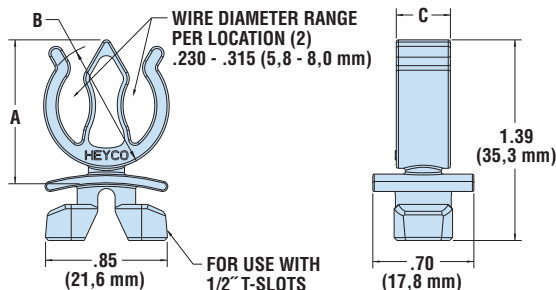


- All new Quarter-Turn Mount (QTM-5) products, designed to work with the standard Powermation rail and racking systems for industrial automation and robotics workstations.
- QTM-5 could be used in any 1/2" T-Slot racking or rail system from other manufacturers.
- Simple application by hand with quick twist 90° swivel for friction fit hold in place – high pull out retention.
- Simply twist to remove for routing and location adjustment.
- Material choices cover a number of application requirements for flammability and temperature.

Helios QTM-5

- Holds up to 2 cables between .230 - .315" (5,8 - 8,0 mm) each.
- Cables install with fingertip pressure.
- Design provides high axial retention with one cable and even better with both cable bays filled.

SBCQTM-5

BUNDLE DIAMETER		Nylon 6/6 Natural	PART NO. HS Nylon 6/6 Black	VO Nylon 6/6 Black	DESCRIPTION	PART DIMENSION					
in.	mm.					A Height in. mm.	B Width in. mm.	C Depth in. mm.			
.29	7,4	.44	11,2	15486	15486B	15486F	SBCQTM-5 437	1.03 26,2	1.12 28,4		
.41	10,4	.69	17,5	15490	15490B	15490F	SBCQTM-5 687	1.18 30,0	1.24 31,5	.31	7,9
.60	15,2	.88	22,2	15494	15494B	15494F	SBCQTM-5 875	1.51 38,4	1.66 42,2		

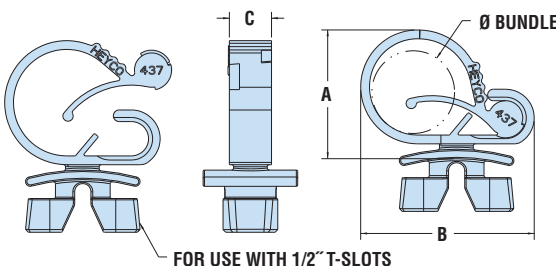

SBCQTM-5



- Wide cable diameter range handles multiple applications.
- Releasable and reusable.
- Secure clamping will not release easily.
- Locking feature prevents twisting apart.

CHQTM-5 L

- Gather and direct single or bundles of wires at low cost.
- Vertical for top entry and narrow width for easy application of wires and small footprint.
- Latch gate locks cables in place.
- Latch gate releasable for repair, replace or addition to previously placed wires.

CHQTM-5 L

WIRE CAPACITY		Nylon 6/6 Natural	PART NO. HS Nylon 6/6 Black	VO Nylon 6/6 Black	DESCRIPTION	PART DIMENSION				
in.	mm.					A Height in. mm.	B Width in. mm.	C Depth in. mm.		
.44 x .14	11,1 x 3,6	4421	4421B	4421F	CHQTM-5 L-12	.50 12,7				
.44 x .33	11,1 x 8,4	4426	4426B	4426F	CHQTM-5 L-18	.74 18,8				
.44 x .69	11,1 x 17,5	4431	4431B	4431F	CHQTM-5 L-27	1.09 27,7	.61 15,5	.22 5,6		
.44 x 1.00	11,1 x 25,4	4436	4436B	4436F	CHQTM-5 L-35	1.40 35,6				

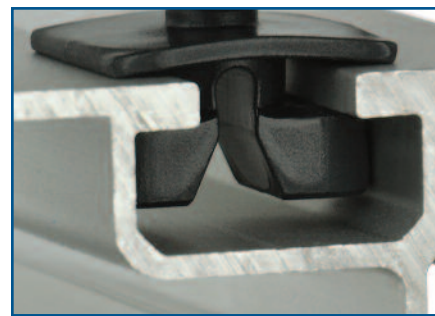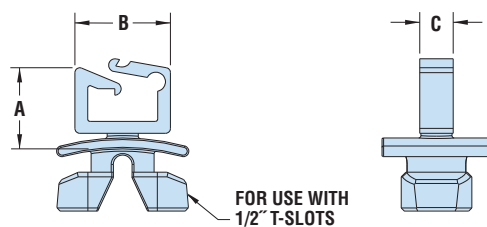

Material	Natural Nylon 6/6	Black Heat Stable / UV Stable Nylon	Black Nylon 6/6
Flammability Rating	UL 94 V-2	UL 94 V-2	UL 94 V-0
Temperature Range	32°F (0°C) to 185°F (85°C)	-40°F (-40°C) to 239°F (115°C)	-40°F (-40°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[15486F](#) [4436F](#) [4426F](#) [S6639](#) [15486B](#) [4436B](#) [4426B](#) [4431B](#) [S6639B](#) [15490F](#) [15494B](#) [4421B](#) [15490B](#) [4431F](#)
[S6639F](#) [15494F](#) [4421F](#)