
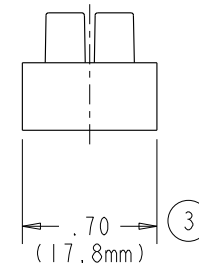


.32
(8,2mm)

Ø .12
(3,0mm)

(3)

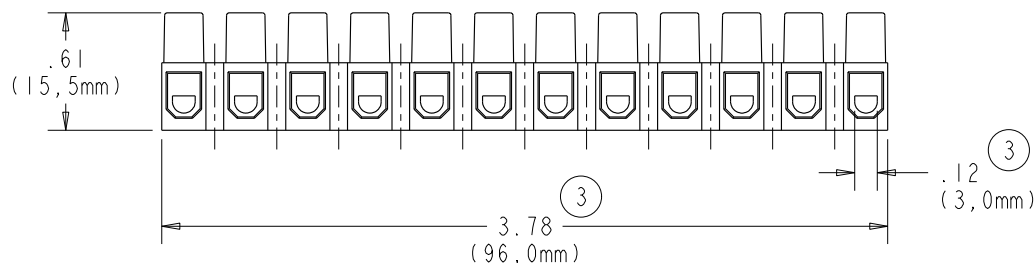

PART NUMBER	DESCRIPTION	MATERIAL	COLOR
9393	TB 0B-WP-12P	NYLON 6/6 94V-2	NATURAL

NOTE:
DIMENSIONS IN PARENTHESES ARE APPROXIMATE
METRIC CONVERSIONS ROUNDED OFF TO ONE PLACE
AND THE GENERAL TOLERANCES DO NOT APPLY.

INCH TOLERANCE UNLESS OTHERWISE SPECIFIED: .XX± .015 .XXX± .005 ANGULAR± 1°

MILLIMETER TOLERANCE UNLESS OTHERWISE SPECIFIED: 0-10 ± .2; 10.01-30 ± .35; ABOVE 30 ± .5

MATERIAL:	<div><div>HEYCO PRODUCTS, INC. TOMS RIVER, NEW JERSEY</div></div> <p>HEYCO PRODUCTS, INC. claims proprietary rights to the material disclosed hereon. This drawing and/or technical information is the property of HEYCO PRODUCTS, INC. is issued in confidence for use only as authorized, and may not be reproduced or described or shown to others without written permission from HEYCO PRODUCTS, INC.</p>	DESCRIPTION:	<div>9393</div> <div>PART No.</div> <div>REV.: 3</div>
HOUSING: SEE TABLE		CUSTOMER DRAWING FOR TERMINAL BLOCK 12-POLE WITH WIRE PROTECTOR	
INSERT: STEEL (ZN PLATED)			
SCREWS: M2,5 STEEL (ZN PLATED)			
CLAMPING AREA: 0,5-2,5mm ²			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[9393](#)