

**A13-203**

**CE**

**USB**



### FEATURES

**\* RATING:**

Input: 12V/24V DC

USB output:

**A13-203A:** 5V DC 2.5A max, 1 or 2 ports.

**A13-203B:** 5V DC 3.1A max, 1 or 2 ports.

**A13-203C:** 5V DC 4.2A max, 1 or 2 ports.

**\* MATERIAL**

Housing: ABS ( UL 94-HB ).

Top contact: nickel plated metal.

Spring contact: nickel plated spring steel.

\* Suitable for most mobile phones and consumer electronic devices.

\* LED power indicator inside.


\* Foldable design.

\* Fits with  $\varnothing$  12mm / 21mm / 22mm sockets.

\* Fits car socket only with dust-proof cover.

\* 2 positions adjustable plug.

\* With 3A glass tube fuse max.

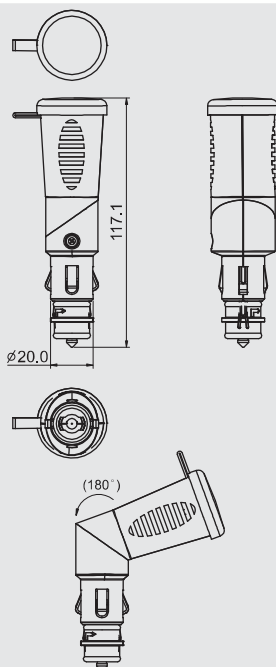

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-203C](#)