
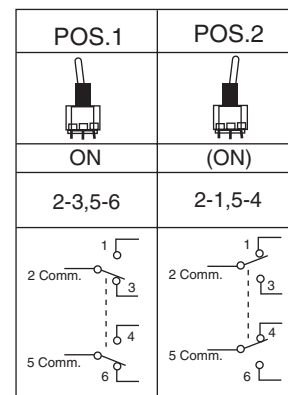
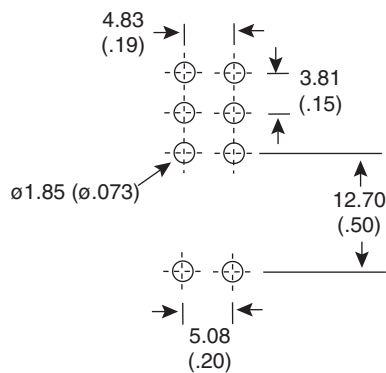
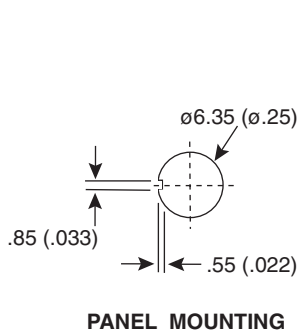


Dimensions: mm (in)

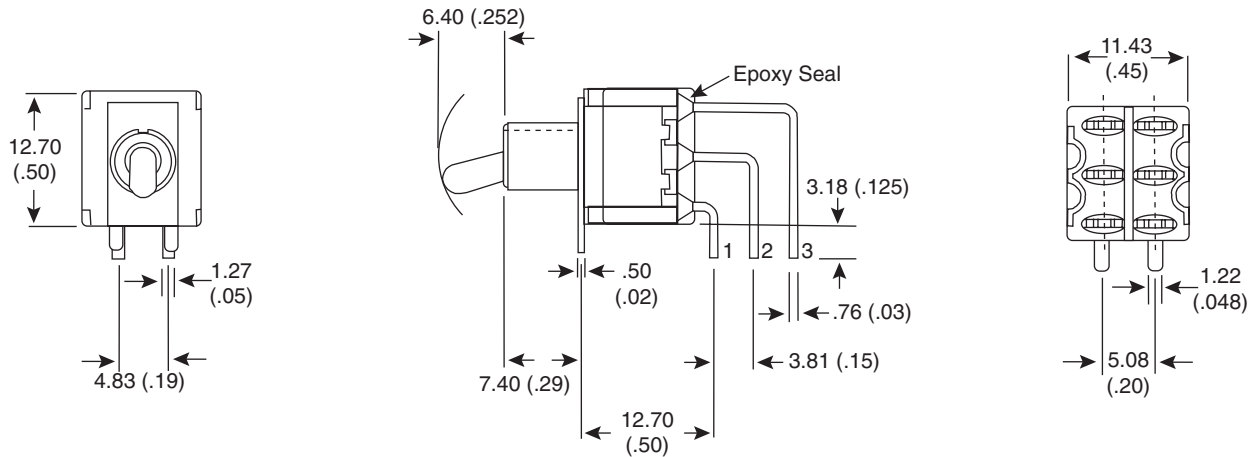

SWITCH FUNCTION

Electrical Specifications:

- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Dielectric Strength: 1,000 V RMS @ sea level
- Rating: 2A/250VAC; 5A/120VA or 28VDC

Mechanical Specifications:

- Operating Temperature: -30°C to 85°C

Note:

- RoHS compliant by exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless Steel
- Terminal / Contact: Silver plated
- Switch Support: Brass, tin plated

Toggle Switch
108-1MD2T2B4M7QE-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1MD2T2B4M7QE-EVX](#)