


Dimensions: mm (In.)

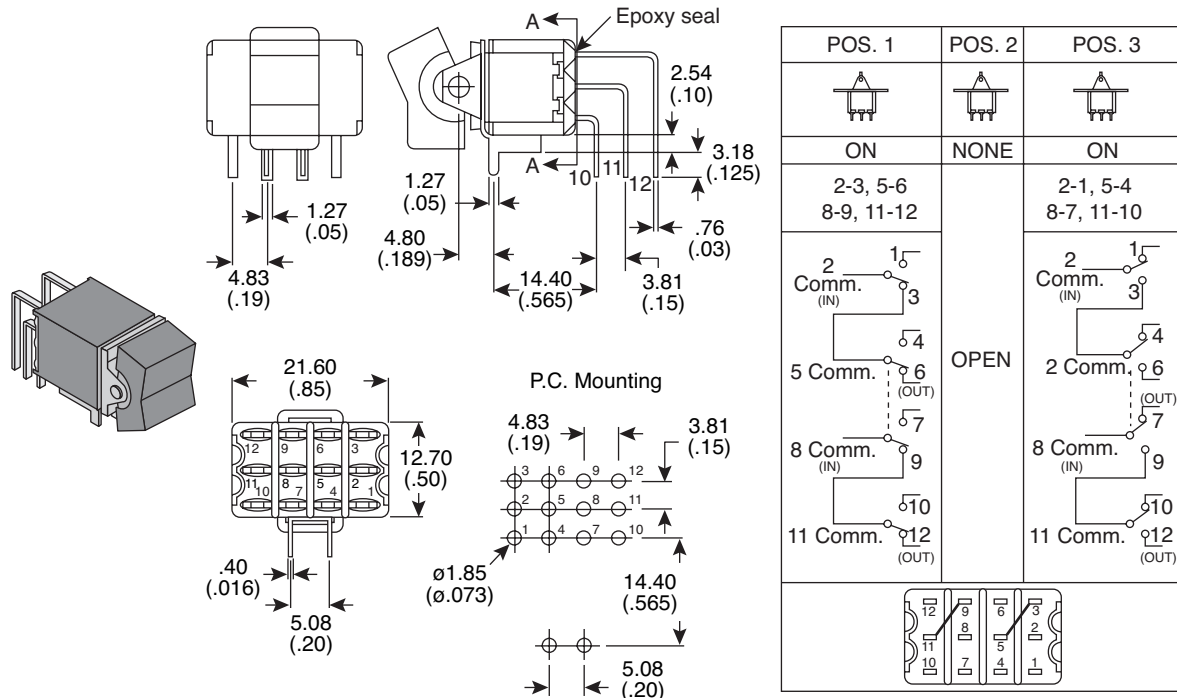

Mechanical Specifications:

- Mechanical Life: 50,000 make-and-break cycles.
- Operating Temperature: -30°C to 85°C

Note:

- RoHS Compliant by Exemption

Electrical Specifications:

- Rating: 2A 250VAC; 5A 120VAC or 28VDC
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS @ sea level

Materials:

- Case: dially phthalate (DAP)
- Actuator: nylon, black std. internal o-ring seal standard with all actuators
- Bushing: brass, nickel plated
- Housing: stainless steel
- Switch Support: brass, tin plated.
- Terminals / Contact: brass, silver, or gold plated

Miniature Rocker Switch
103-7000-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-7000-EVX](#)