



Dimensions: mm (In.)

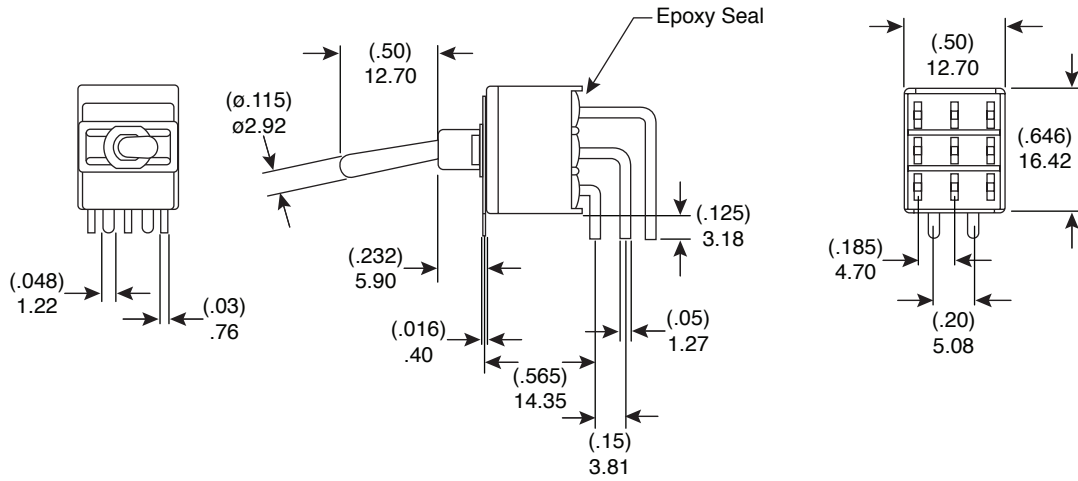

Switch Function

POS.1	POS.2	POS.3
ON	OFF	ON
2-3, 5-6, 8-9	OPEN	2-1, 5-4, 8-7

P.C. Mounting

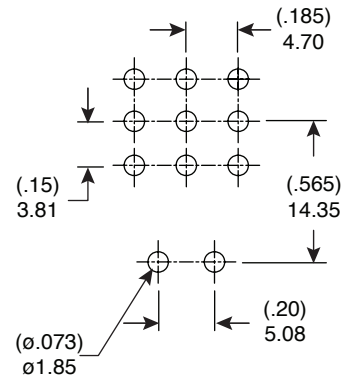

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Electrical Specifications:

- Rating: 2A / 250VAC, 5A / 120 VAC or 28 VDC
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@sea level

Note:

- RoHS Compliant by Exemption

Sealed Miniature Toggle Switch  
108-1A33T1604-EVX



Available from Mouser Electronics

www.mouser.com

1-800-346-6873

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1A33T1604-EVX](#)