
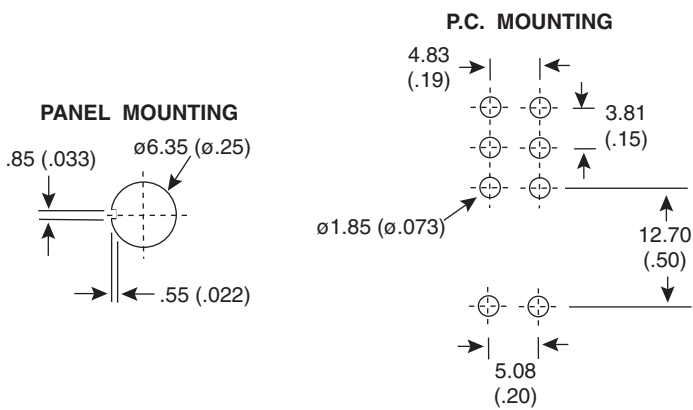


Dimensions: mm (In)

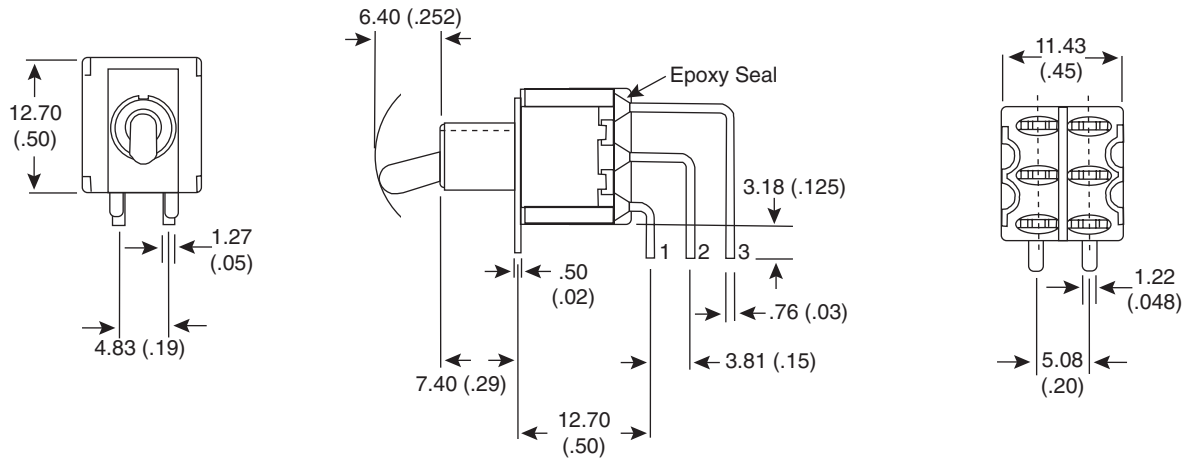

SWITCH FUNCTION

POS.1	POS.2	POS.3
ON	NONE	ON
2-3,5-6	OPEN	2-1,5-4

Electrical Specifications:

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Dielectric Strength: 1,000 V RMS @ sea level.
- Rating: 2A/250 VAC, 5A/120VAC or 28VDC

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver or Gold plated.
- Switch Support: Brass, Tin plated.

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Note:

- RoHS compliant by exemption

Toggle Switch
108-1MD1T2B4M7QE-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1MD1T2B4M7QE-EVX](#)