


Dimensions: mm (in.)

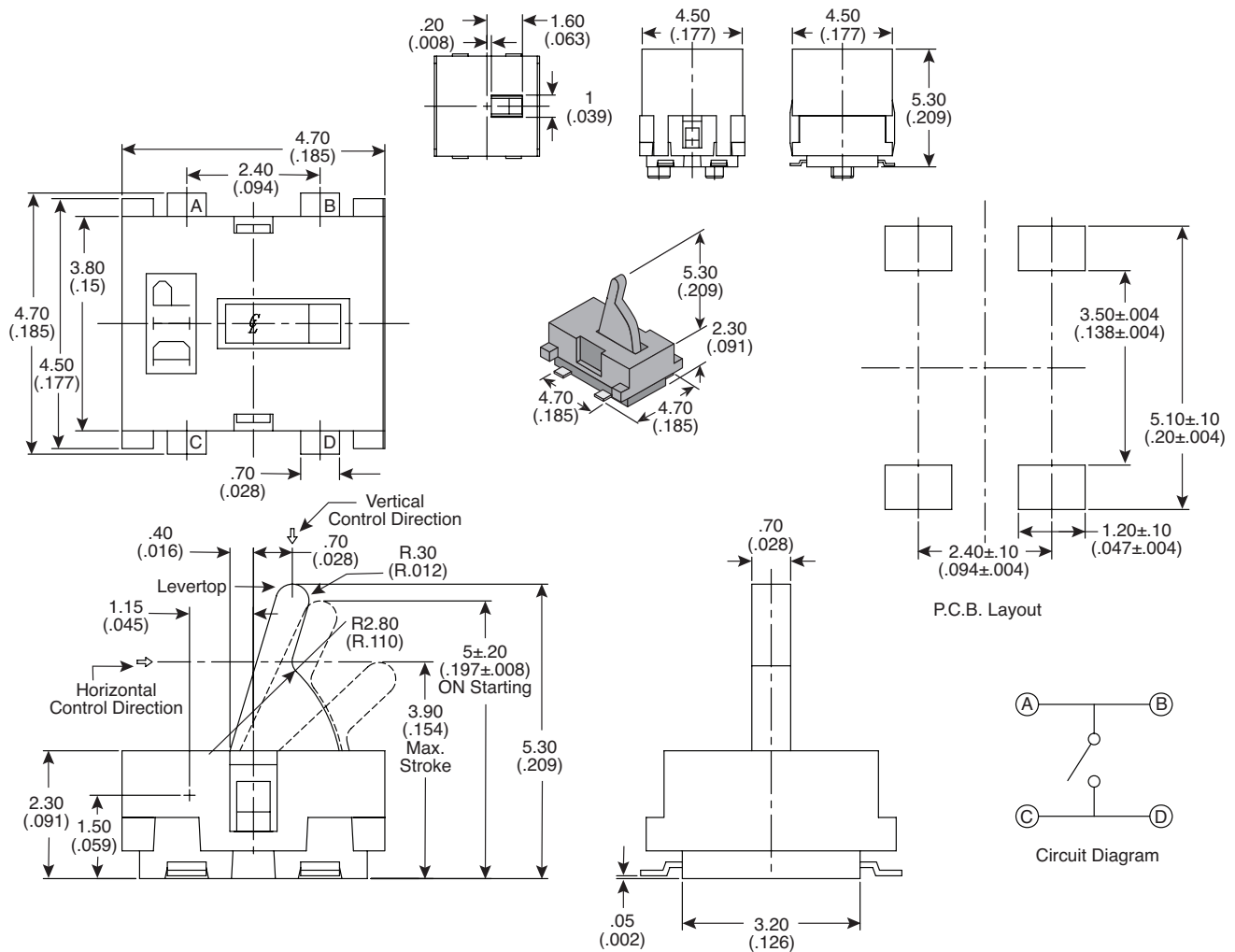

**Electrical Specifications:**

- Rating: 1mA/5V DC
- Contact Resistance: 1Ω Max.
- Insulation Resistance: 100MΩ Min.
- Dielectric Strength: 100 VAC (50Hz or 60Hz) shall be applied across terminals and cover for 1 minute
- Electrical Life: 100,000 cycles

**Mechanical Specifications:**

- Operating Temperature: -10° C to +60° C
- Operating Force: 40gf Max.
- Storage Temperature: -20° C to +70° C
- Stroke: 3.90mm Max.

**Note:**

- RoHS Compliant

Detector Switch  
104-ATE1K-EV



Available from Mouser Electronics

www.mouser.com

1-800-346-6873

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[104-ATE1K-EV](#)