
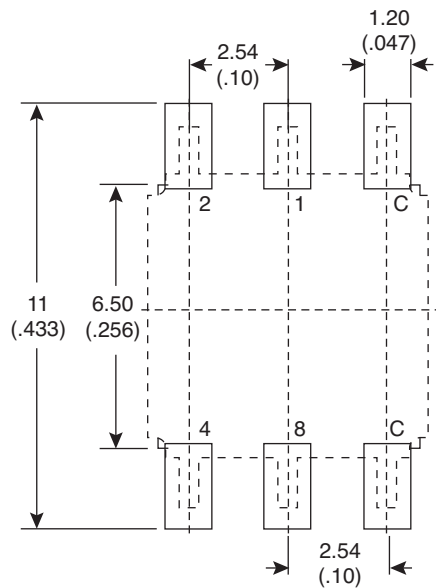
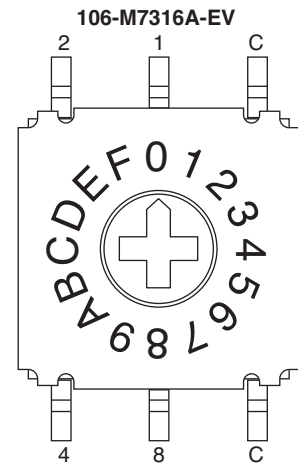
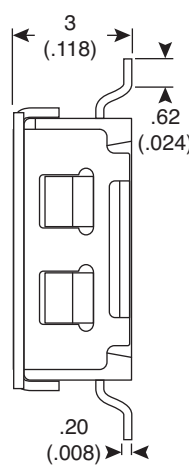


Dimensions: mm (in.)

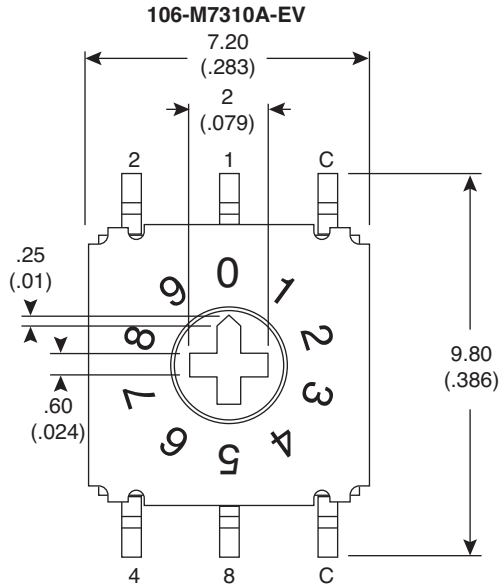

P.C.B. Layout

TYPE	POSITION	CODE				
		1	2	4	5	
10 STEP	0	●	●	●	●	○
	1	○	●	●	●	○
	2	●	○	●	●	○
	3	○	○	●	●	○
	4	●	●	○	●	○
	5	○	●	○	●	○
	6	●	○	○	●	○
	7	○	○	○	●	○
16 STEP	8	●	●	●	○	○
	9	○	●	●	○	○
	A	●	○	●	○	○
	B	○	○	●	○	○
	C	●	●	○	○	○
	D	○	○	●	○	○
E	●	○	○	○	○	
F	○	○	○	○	○	

Circuit Chart

Electrical Specifications:

- Rating:
Non-Switching: 100mA/50V DC
Switching: 25mA/24V DC
- Contact Resistance: 100mΩ Max. (initial)
- Dielectric Strength: 250V AC for 1 min.
- Insulation Resistance: 100MΩ min. @ 250V DC

Mechanical Specifications:

- Operating Temperature: -25°C - +80°C
- Storage Temperature: -40°C - +85°C
- Operation Force: 200gf cm Max.

Note:

- RoHS Compliant

Rotary Dip Switches
106-M7310A-EV, 106-M7316A-EV



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[106-M7310A-EV](#) [106-M7316A-EV](#)