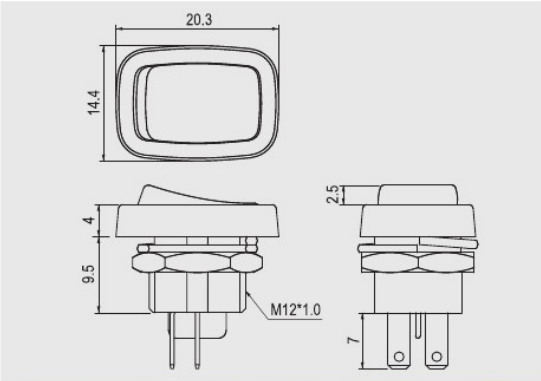
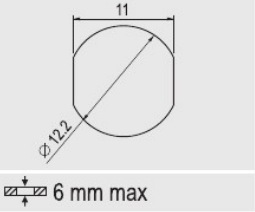


R13-213

Screw Type



 
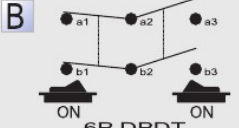
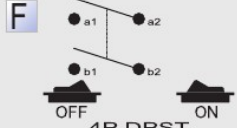
Rating
6A 125V AC 3A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out



FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Specially for compact room design.
- * Mounted by nut.

R13-213  -  

FUNCTION		TERMINAL
A  2P SPST	C  3P SPDT	0 3  .110" SQ
B  6P DPDT	F  4P DPST	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[R13-213B-03-BB](#) [R13-213A-03-BB](#) [R13-213B-03-BR](#) [R13-213A-03-BR](#) [R13-213C-03-BB](#) [R13-213F-03-BB](#)