


Dimensions: mm (In)

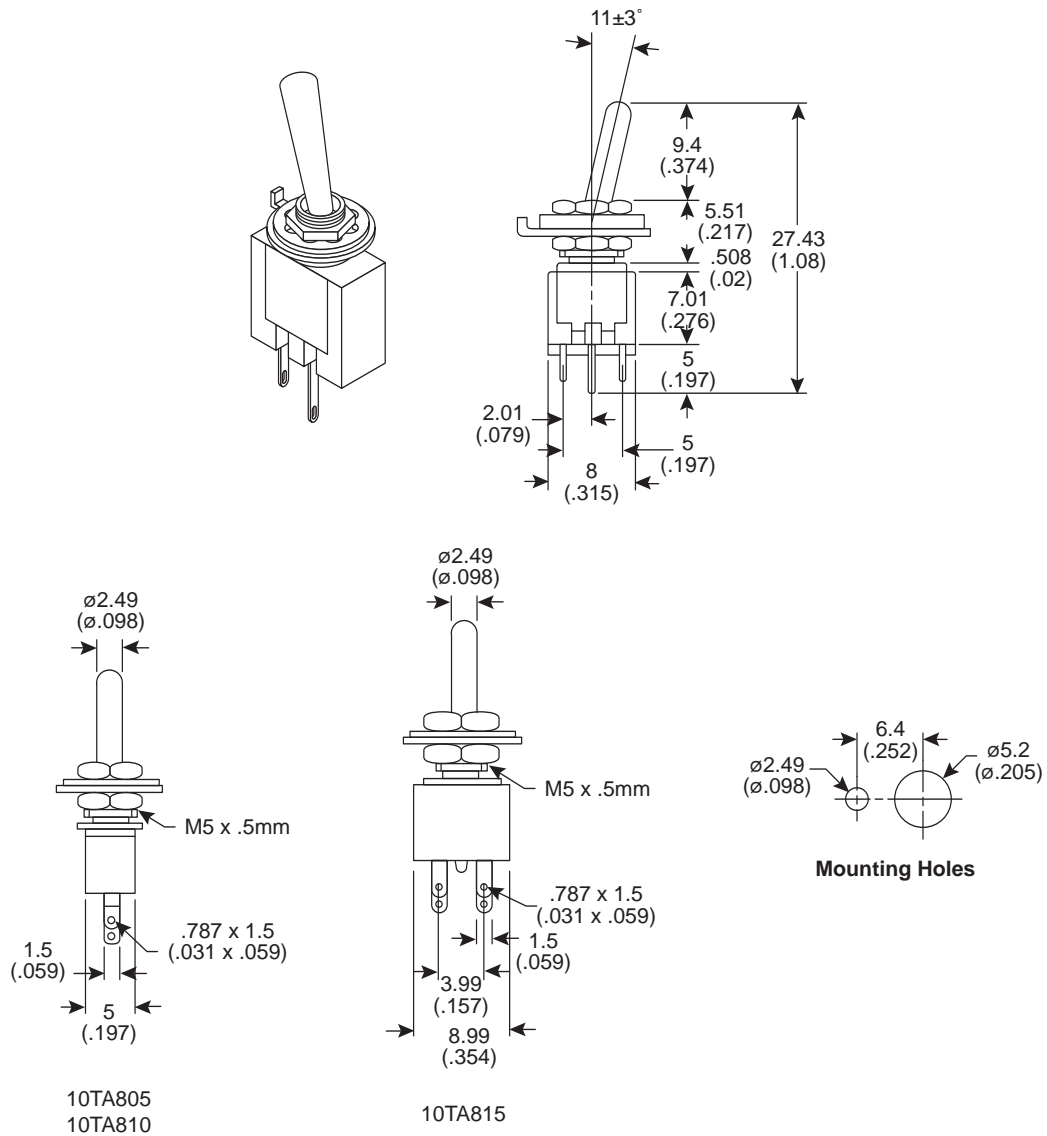

**Electrical Specifications:**

- Rating: 3A/125VAC
- Insulation resistance: 100M $\Omega$  min. @500VDC
- Dielectric strength: 1000VAC for 1 minute
- Contact resistance: 20m $\Omega$  max. @ 2.5VDC 1A

| Mouser Stock No. | Type    | Circuit |
|------------------|---------|---------|
| 10TA805          | 2P SPST | On-Off  |
| 10TA810          | 3P SPDT | On-On   |
| 10TA815          | 6P DPDT | On-On   |

**Sub-Miniature Toggle Switches**  
10TA805, 10TA810, 10TA815



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[10TA810](#) [10TA815](#) [10TA805](#)