




D-SUBMINIATURE CONNECTORS:
K42X Series
 Dual-Port D-Sub Combo

K42X-B25P/E9P-A4N Dimensions
 Dimensions in mm

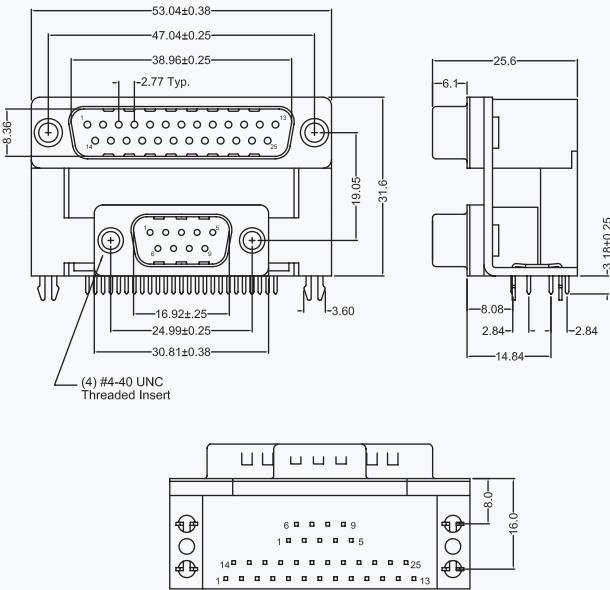

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

<input type="text"/>	-	<input type="text"/>	<input type="text"/>	<input type="text"/>	<input type="text"/>	<input type="text"/>
Series		Top Shell Size	Bottom Shell Size	Center Distance	Boardlock Option	Jackscrews Option

Series

K42X - Dual-Port D-Subminiature Connector

Top/Bottom Shell Size

25/9 - 25 Contacts over 9 Contacts

Top/Bottom Connector Type

- P/P - Plug/Plug
- P/S - Plug/Receptacle
- S/P - Receptacle/Plug
- S/S - Receptacle/Receptacle

Center to Center Distance

A - 0.750" (Standard)

Boardlocks Option

4N - Boardlocks (Standard)

Jackscrews Option

- Blank** - No Jackscrews
- J** - #4-40 Jackscrews Installed

Contact Kycon for Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[K42X-B25P/E9S-A4N](#) [K42X-B25P/E9P-A4N](#) [K42X-B25P/E9P-A4NJ](#) [K42X-B25P/E9S-A4NJ](#)