 


Datasheet

LL01CR-DKYxxL02

Available Distribution



 
LED



Recommend Applications



General Information




- Lens Material PC LEV1700KL
- Operating Temperature -40°C~+110°C
- UL Flammability V-2 @1.5mm
- UL RTI Elec 130°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ☑ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Dimensions

Part Number	Diameter	Height
LL01CR-DKYxxL02	Ø75	16.6

*All dimensions are in millimeters.

Packaging Details (SPQ)

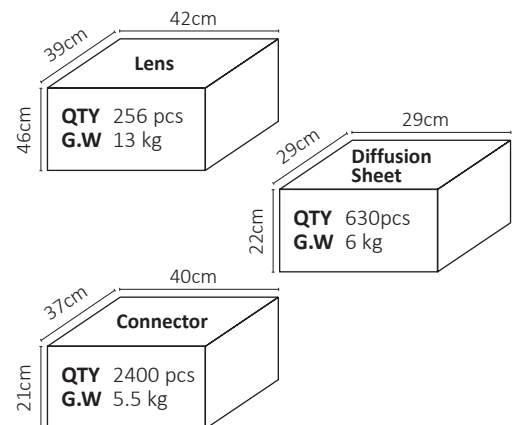

Accessories




- Available with Connector LL01CRWF15H2
- Available with Diffusion Sheet LL01CR-DKYxxL02 (15°/24°/38°/10°x60°/30°x60°)

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL01CR-DKY10L02

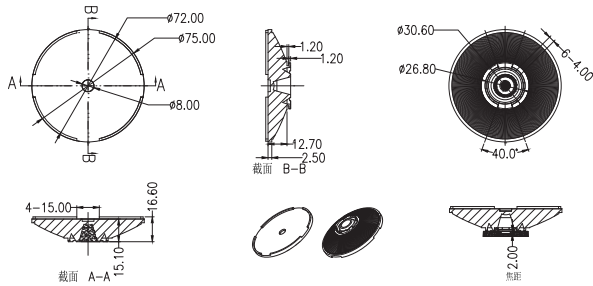


Diffusion Sheet Dimension

LL01CR-DKYxxL02 (15°/24°/38°/10°×60°/30°×60°)

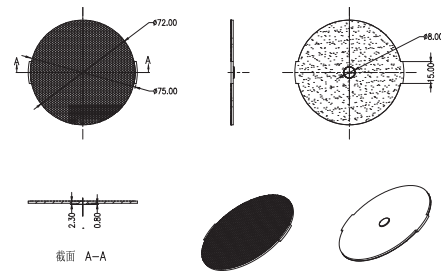

Connector Dimension


LL01CRWF15H2

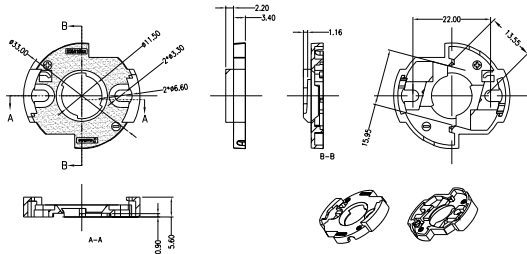

Assembly Instruction

Fixing Method

Part No LL01CR-DKYxxL02
 Lens LL01CR-DKY10L02
 Diffusion Sheet LL01CR-DKYxxL02 (15°/24°/38°/10°×60°/30°×60°)
 Connector LL01CRWF15H2

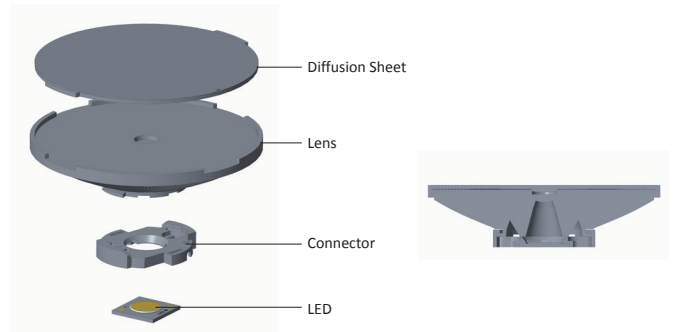


Photometric Distribution




CREE
CXA1520

Distribution


10°

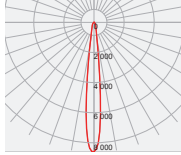


15°

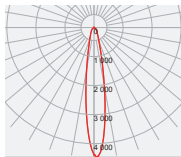


24°

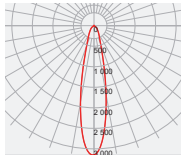


38°

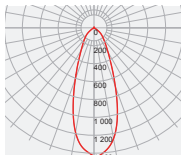


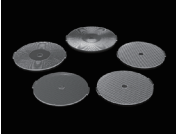

10°x60°

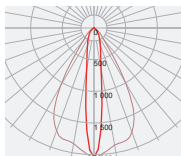


30°x60°

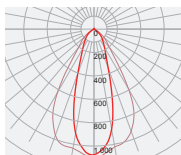


Details by LED

Part No	Connector	Diffusion Sheet	LED Size	LED
LL01CR-DKY××L02	 <p>LL01CRWF15H2</p>	 <p>LL01CR-DKY××L02 (15°/24°/38°/10°×60°/30°×60°)</p>	LES Ø9	 <p>CREE CXA1520</p>

LED	Part No	FWHM	cd / lm	IES
 <p>CREE CXA1520</p>	LL01CR-DKY10L02	11°	8.5	↓
	LL01CR-DKY15L02	16°	4.4	↓
	LL01CR-DKY24L02	22°	3.1	↓
	LL01CR-DKY38L02	37°	1.4	↓
	LL01CR-DKY1060L02	14°×60°	2.0	↓
	LL01CR-DKY3060L02	33°×61°	1.1	↓

Product Nomenclature

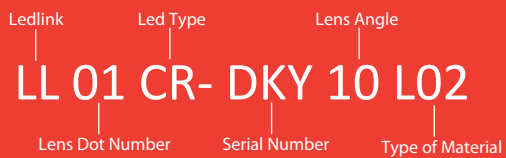

Ledlink Optics, Inc Taiwan HQ

15F, No.655, Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd Dongguan Factory

No.5, TianKeng Industrial Dist., HengLiTown, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LedLink Optics:](#)

[LL01CR-DKY1060L02-M2](#) [LL01CR-DKY10L02](#) [LL01CR-DKY24L02-M2](#) [LL01CR-DKY3060L02-M2](#) [LL01CR-DKY15L02-M2](#) [LL01CR-DKY38L02-M2](#) [LL01CR-DKY15L02](#)