 




Datasheet

LL01ZZ-DBG××L06-M2-T

Available Distribution



Dimensions


Part Number	Diameter	Height
LL01ZZ-DBG××L06	Ø35	16.3
LL01ZZ-DBG××L06-M2-T	Ø37.5	20

*All dimensions are in millimeters.


LED



Packaging Details (SPQ)

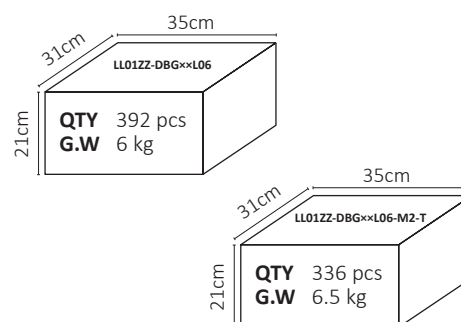

Recommand Applications

 

General Information



- Lens Material PMMA 8N
- Operating Temperature -40°C~+70°C
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Accessories



- Available with Holder LL01CRWG15H2
- Available with Tape LL01A00YUXX


Mechanical Specification

*All dimensions are in millimeters.

Lens Dimension




LL01ZZ-DBG××L06

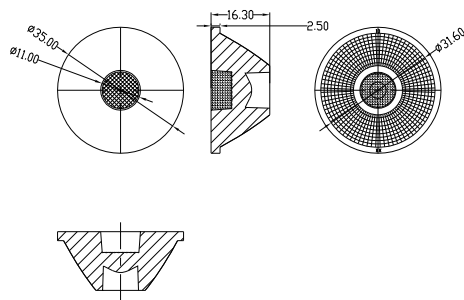

Assembly Instruction

Fixing Method

Part No LL01ZZ-DBG××L06

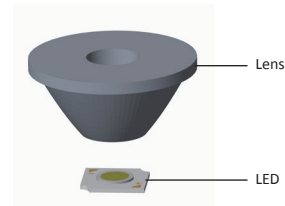


Place the bottom of the lens above heat-sink with distance 1.4mm.

Holder Dimension




LL01CRWG15H2

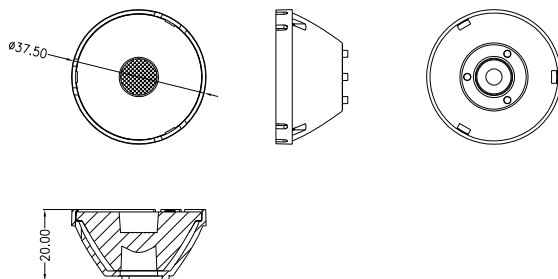


Assembly Instruction

Fixing Method


Part No LL01ZZ-DBG××L06-M2-T
Holder LL01CRWG15H2
Tape LL01A00YUXX

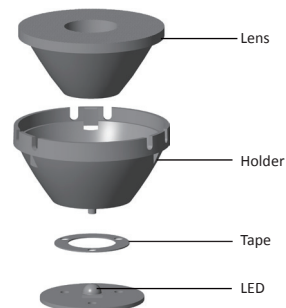

Photometric Distribution

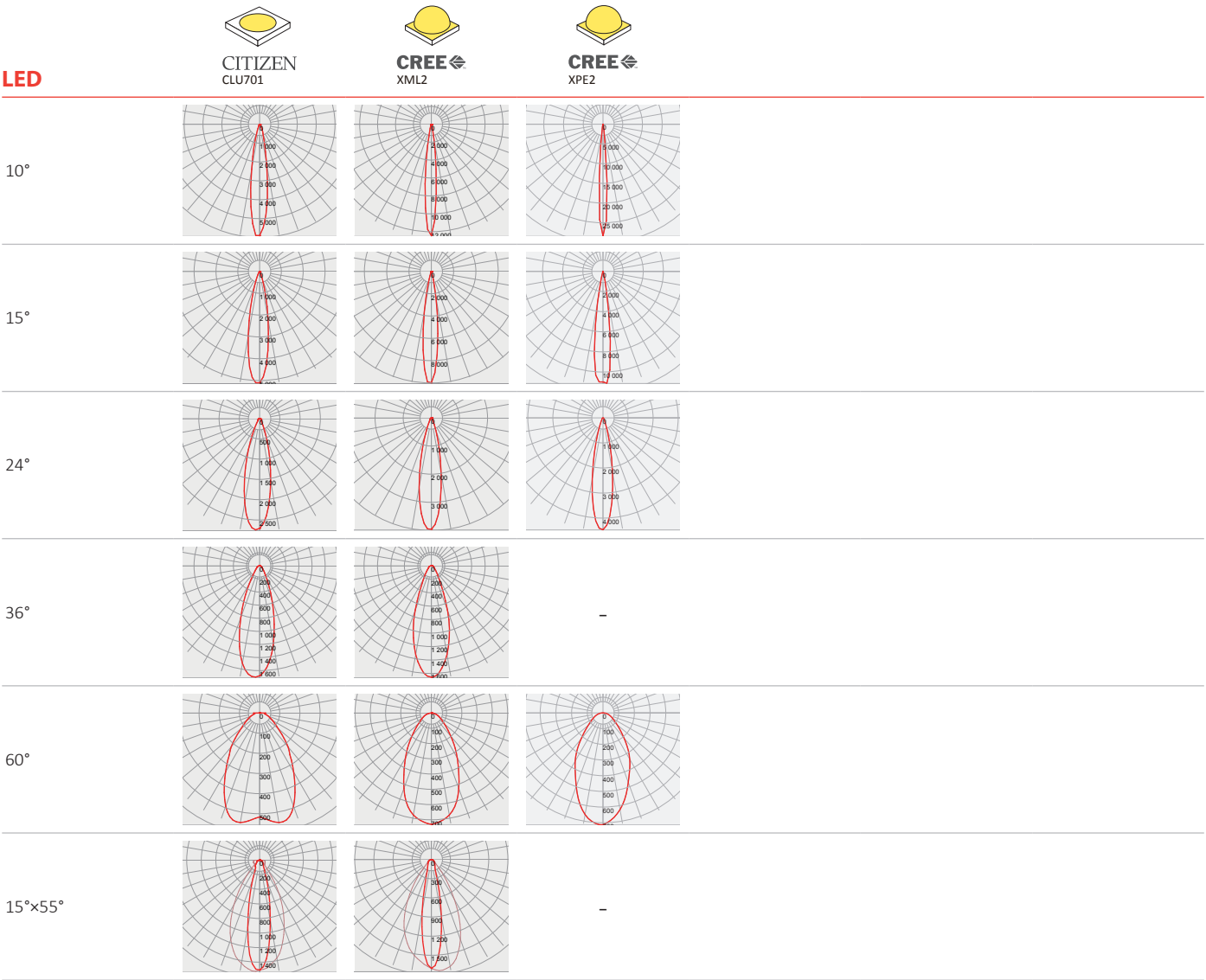

Details by LED

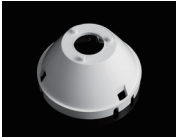Part No	Holder	Tape	LED Package Size	LED
LL01ZZ-DBGxxL06	-	-	LES Ø6	 CITIZEN CLU701
LL01ZZ-DBGxxL06-M2-T	 LL01CRWG15H2	 LL01A00YUXX	3535 / 5050	 CREE XML2  CREE XPE2

LED	Part No	FWHM	cd / lm	IES
 CITIZEN CLU701	LL01ZZ-DBG10L06	17°	5.8	
	LL01ZZ-DBG15L06	20°	5.1	
	LL01ZZ-DBG24L06	26°	2.7	
	LL01ZZ-DBG36L06	35°	1.6	
	LL01ZZ-DBG60L06	68°	0.5	
	LL01ZZ-DBG1555L06	23°x53°	1.5	
 CREE XML2	LL01ZZ-DBG10L06-M2-T	11°	12.4	
	LL01ZZ-DBG15L06-M2-T	15°	9.9	
	LL01ZZ-DBG24L06-M2-T	22°	3.9	
	LL01ZZ-DBG36L06-M2-T	36°	1.6	
	LL01ZZ-DBG60L06-M2-T	56°	0.7	
	LL01ZZ-DBG1555L06-M2-T	20°x55°	1.7	
 CREE XPE2	LL01ZZ-DBG10L06-M2-T	7°	28.3	
	LL01ZZ-DBG15L06-M2-T	14°	11.1	
	LL01ZZ-DBG24L06-M2-T	20°	4.4	
	LL01ZZ-DBG36L06-M2-T	-	-	-
	LL01ZZ-DBG60L06-M2-T	58°	0.7	
	LL01ZZ-DBG1555L06-M2-T	-	-	-

Product Nomenclature

Ledlink	Led Type	Lens Angle	Holder	
LL	01	ZZ	-DBG	10 L06 -M2 -T
Lens Dot Number	Serial Number	Type of Material	Tape	

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LedLink Optics:](#)

[LL01ZZ-DBG24L06-M2-T](#) [LL01ZZ-DBG10L06](#) [LL01ZZ-DBG1555L06](#) [LL01ZZ-DBG60L06-M2-T](#) [LL01ZZ-DBG36L06](#)
[LL01ZZ-DBG36L06-M2-T](#) [LL01ZZ-DBG15L06-M2-T](#) [LL01ZZ-DBG1555L06-M2-T](#) [LL01ZZ-DBG24L06](#) [LL01ZZ-](#)
[DBG60L06](#) [LL01ZZ-DBG15L06](#) [LL01ZZ-DBG10L06-M2-T](#)