 




Datasheet

LL01ZZ-DGW××L06

Available Distribution



Dimensions


Part Number	Diameter	Height
LL01ZZ-DGW××L06	Ø22	12

*All dimensions are in millimeters.

LED



Packaging Details (SPQ)

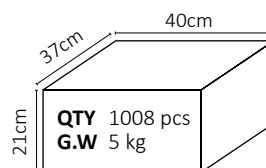

Recommnd Applications



General Information

PMMA 70°C -40°C	PMMA 8N HB 1.5mm RTI 90°C	400nm~900nm > 90%		
-----------------------	---------------------------------	----------------------	--	--


- Lens Material PMMA 8N
- Operating Temperature -40°C~+70°C
- UL Flammability HB @1.5mm
- UL RTI Elec 90°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Mechanical Specification

*All dimensions are in millimeters.

Lens Dimension

LL01ZZ-DGW××L06

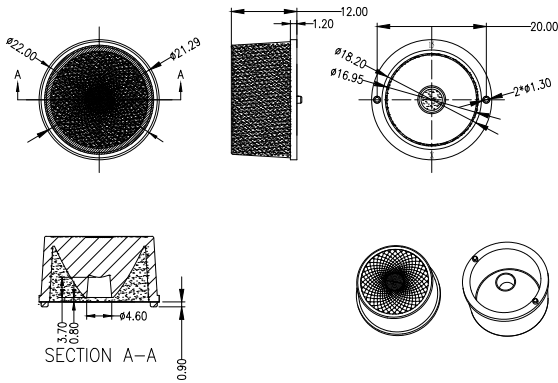


Assembly Instruction

Fixing Method

Part No LL01ZZ-DGW××L06
LED CREE XP-E2 / OSRAM SSL80



Luminarie Accessories

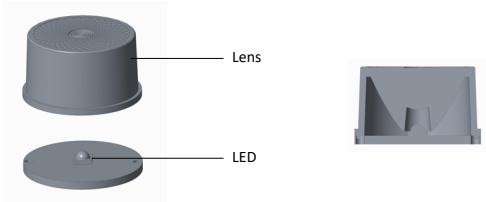


Assembly Instruction

Fixing Method


Part No LL01ZZ-DGW××L06
LED OSRAM DURIS S5



Luminarie Accessories

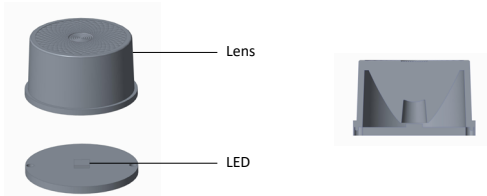

Photometric Distribution

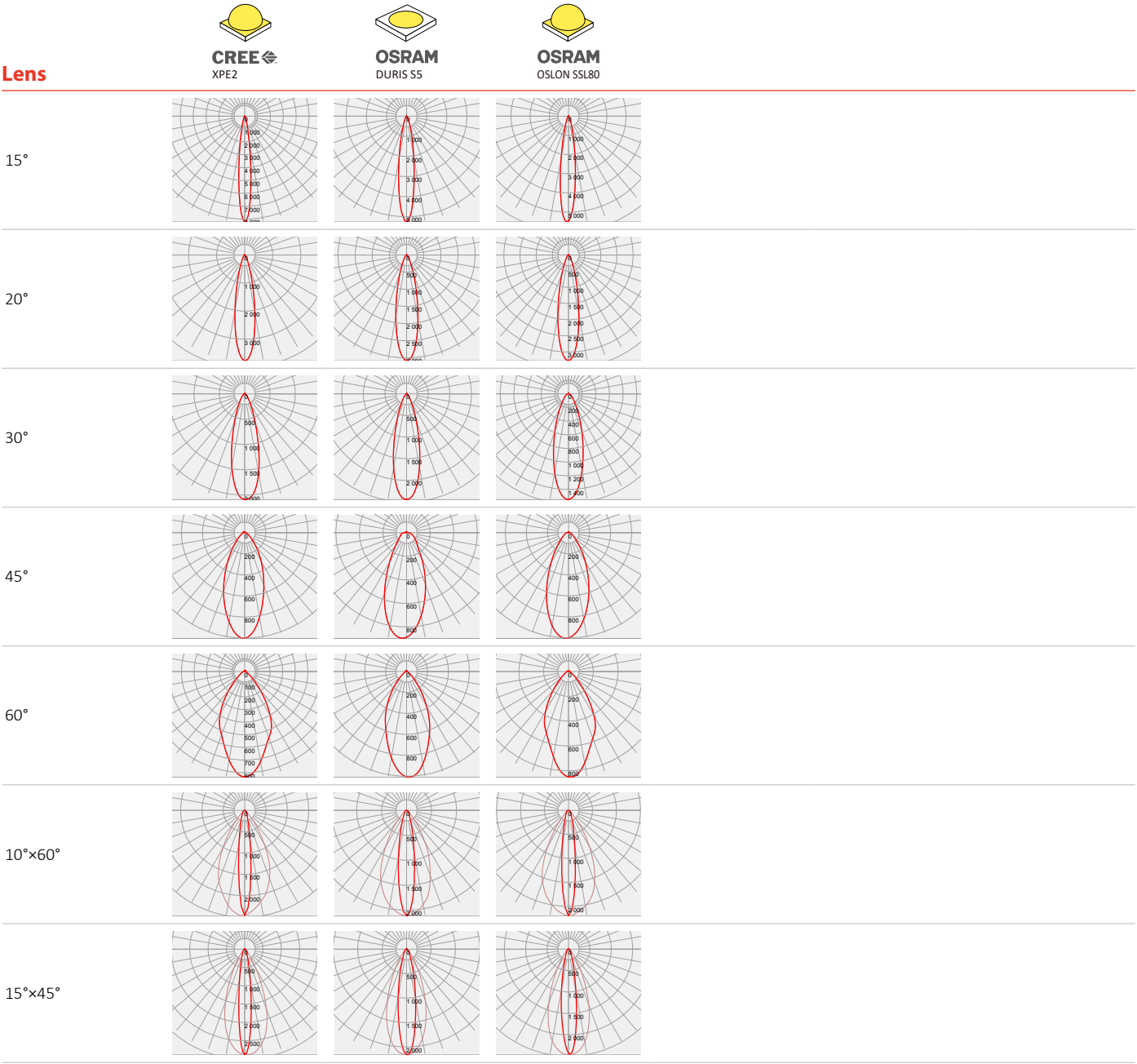

Details by LED

Part No	Accessories	LED Package Size	LED
LL01ZZ-DGWxxL06	-	3030 / 3535 LES Ø2.6	 CREE XPE2  OSRAM DURIS S5  OSRAM OSOLON SSL80

LED	Part No	FWHM	cd / lm	IES
 CREE XPE2	LL01ZZ-DGW15L06	13°	8.2	↓
	LL01ZZ-DGW20L06	21°	3.7	↓
	LL01ZZ-DGW30L06	29°	2.0	↓
	LL01ZZ-DGW45L06	44°	1.0	↓
	LL01ZZ-DGWG60L06	57°	0.8	↓
	LL01ZZ-DGW1060L06	13°×54°	2.4	↓
	LL01ZZ-DGW1545L06	13°×43°	2.8	↓
 OSRAM DURIS S5	LL01ZZ-DGW15L06	16°	5.2	↓
	LL01ZZ-DGW20L06	23°	3.0	↓
	LL01ZZ-DGW30L06	28°	2.4	↓
	LL01ZZ-DGW45L06	44°	0.8	↓
	LL01ZZ-DGWG60L06	49°	1.0	↓
	LL01ZZ-DGW1060L06	17°×52°	2.1	↓
	LL01ZZ-DGW1545L06	19°×41°	2.1	↓
 OSRAM OSOLON SSL80	LL01ZZ-DGW15L06	16°	5.5	↓
	LL01ZZ-DGW20L06	22°	3.2	↓
	LL01ZZ-DGW30L06	32°	1.5	↓
	LL01ZZ-DGW45L06	46°	1.0	↓
	LL01ZZ-DGWG60L06	56°	0.8	↓
	LL01ZZ-DGW1060L06	14°×53°	2.1	↓
	LL01ZZ-DGW1545L06	16°×42°	2.4	↓

Product Nomenclature

Ledlink Led Type Lens Angle
LL 01 ZZ -DGW 15 L06
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.6, Gaoxin Road, Tiankeng, Hengli Town, Dongguan City,
Guangdong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LedLink Optics:](#)

[LL01ZZ-DGW45L06](#) [LL01ZZ-DGW20L06](#) [LL01ZZ-DGW1060L06](#) [LL01ZZ-DGW15L06](#) [LL01ZZ-DGW30L06](#) [LL01ZZ-DGWG60L06](#) [LL01ZZ-DGW1545L06](#)