

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	3T
Termination type	No contacts / Accessory
IP rating	66
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	BRA*: Blanking cap for fixed sockets
Keying	No keying
Housing Material	
Weight	8.57 g

### Performance

Configuration
Insulator
Rated Current

### Specifications

Contact LEMO for performance details.

### Others


Endurance (Shell): >1000 mating cycles
Humidity (max): ≤95% [at 60 deg C / 140 F]
Resistance to vibration: 15 g [10 Hz - 2000 Hz]
Shock Resistance: 100 g [ 6 ms]
Climatical Category: 50/175/21

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Shielding efficiency (min): 95 dB (at 10 MHz)  
Shielding efficiency (min): 80 dB (at 1 GHz)

---

## DRAWINGS

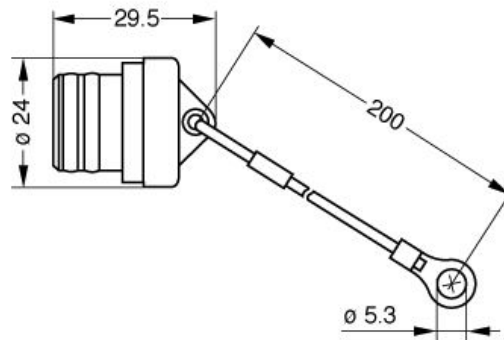

No keying

---

## RECOMMENDED BY LEMO

### Tools

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[BRA.3T.200.PCZN](#)