

## SUMMARY

### # Wires

Low voltage 32



*Image is for illustrative purpose only*

Series	2P
Termination type	Female solder
IP rating	50
AWG wire size	34.00 - 28.00
Cable Ø	7.30 - 9.20 mm
Status	active
Matching parts	<a href="#">CAB.M32.GLA.C92AZ</a>

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	CR*: Free receptacle with cable collet
Keying	3 keys (alpha=0, gamma=60; Plug: male contacts; Receptacle: female contacts)
Housing Material	PSU (Polysulfone), gray
Weight	11.69 g

### Performance

Configuration	2P.M32 : 32 Low V.
Insulator	L: PEEK for solder contacts
Rated Current	1.5 Amps

### Specifications

Contact Type:	Solder
Contact Dia.:	0.5 mm (0.019in)
Bucket Dia.:	0.5 mm (0.019in)
Test voltage (kV rms) Contact-contact:	0.7
Air clearance min.:	0.35 mm
Creepage distance min.:	0.35 mm


### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Endurance (Shell): >1000 mating cycles  
Temp (min / max): -50°C / +150°C  
F ret (min): 150 N  
F ret (max): 250 N  
Steam sterilization: 20 times

---

## DRAWINGS

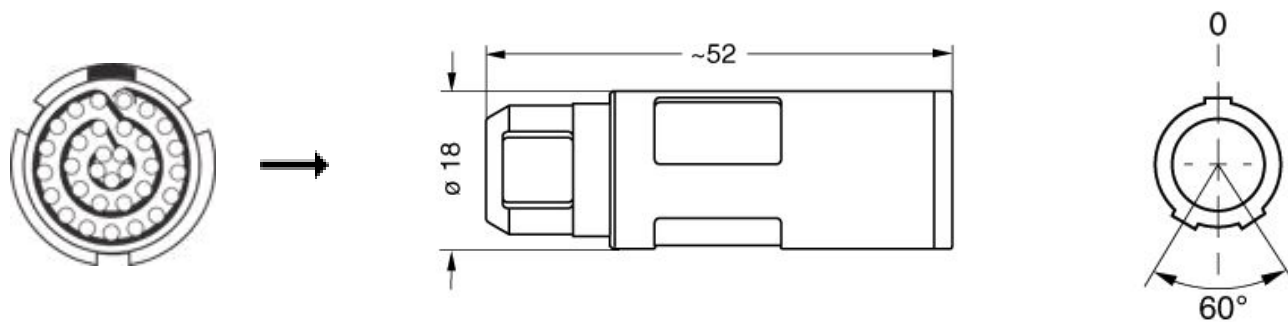

### Dimensions

	A	L
mm.	18	52
in.	0,71	2,05

---

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[CRB.M32.GLL.C92A](#)