

## SUMMARY

### # Wires

Low voltage 10



*Image is for illustrative purpose only*

Series OR  
Termination type Female crimp  
IP rating 50  
AWG wire size 24.00 - 20.00  
Cable Ø 1.60 - 6.20 mm  
Status active  
Matching parts [FGG.OR.310.GLC62](#)

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model EBG\*: Fixed receptacle, key (G) or key (A) with visible shell  
Keying 3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)  
Housing Material Crastin® PBT (Polybutylene terephthalate), gray  
Weight 7.13 g

### Performance

Configuration OR.310 : 10 low voltage  
Insulator L: PEEK (UL 94 / V-0/1.5)  
Rated Current 3.5 Amps



### Specifications

Contact Type: Crimp  
Test voltage (kV rms) Contact-contact: 1.5

### Others

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# DRAWINGS

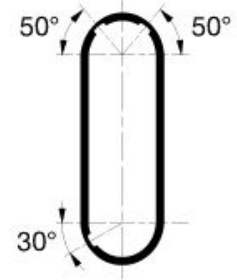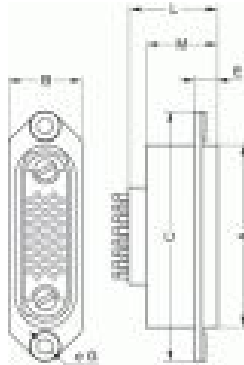

## Dimensions

	A	B	L	M
mm.	18	6	12	7
in.	0,71	0,24	0,47	0,28

# RECOMMENDED BY LEMO

## Tools

- Crimp Tool: [DPC.91.701.V](#)  
Positionner: [DCE.91.090.BVM](#)  
Replacement contact: EGG.2F.660.ZZM

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[EBG.0R.310.GLM](#)