

## SUMMARY

### # Wires

Fiber optic 1



*Image is for illustrative purpose only*

Series 00  
Termination type Fibre optic contact  
IP rating 50  
AWG wire size 0.00 - 0.00  
Cable Ø 0.00 - 0.00 mm  
Status active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model FG\*: Straight plug key (G) or (B) with bend relief included  
Keying 1 key (alpha=0, plug: male contacts, receptacle: female contacts)  
Housing Material Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces  
Weight 8.07 g

### Performance

Configuration FO/BA4 : 1 FO 125 um hole  
Insulator C: Zirconia Ceramic  
Rated Current

### Specifications

Contact Type: F4 (included)  
Ferrule Material: Zirconia Ceramic  
Hole dia.(um): 125  
Core/Cladding (um): 9/125


### Others

Salt Spray Corrosion: >1000 hr

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

---

## DRAWINGS

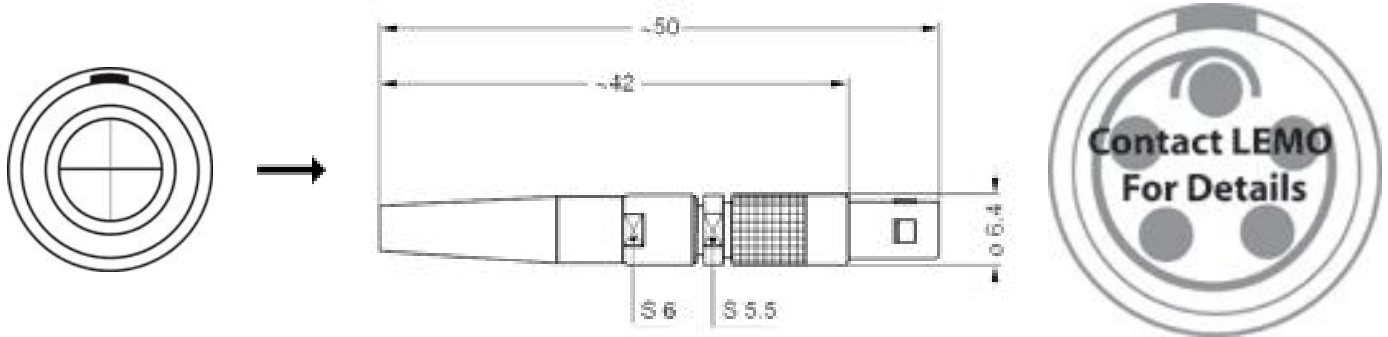

### Dimensions

	A	L	M	S1	S2
mm.	6.4	50	42	5.5	6
in.	0,25	1,97	1,65	0,22	0,24

---

## RECOMMENDED BY LEMO

### Tools

Caps: [BFG.00.100.PCSG](#)

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[FGG.00.BA4.CCBE25N](#)