

SUMMARY

Wires

Fiber optic 4



Image is for illustrative purpose only

Series MH
Termination type No contacts / Accessory
IP rating 68
AWG wire size 0.00 - 0.00
Cable Ø 6.60 - 7.50 mm
Status active
Matching parts [EHE.MH.03C.XLZ](#)

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model FHE*: Straight plug (IP68)
Keying Hermaphroditic keying (half moon insert) with male pin 1
Housing Material Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Weight 55.45 g

Performance

Configuration MH.03C : 4 FO TYPE F2
Insulator
Rated Current

Specifications


Contact LEMO for performance details.

Others

Salt Spray Corrosion: max. 48 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

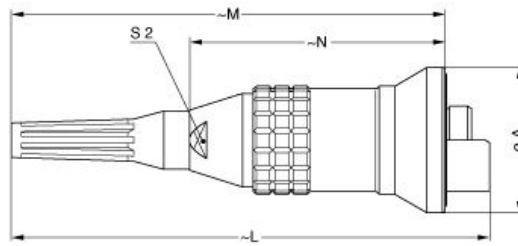

Dimensions

| | A | L | M | N | S2 |
|-----|------|-------|------|------|------|
| mm. | 34 | 109.3 | 98.9 | 56.9 | 15 |
| in. | 1,34 | 4,30 | 3,89 | 2,24 | 0,59 |

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[FHE.MH.03C.XLZT76G](#)