

SUMMARY

Wires

Low	22
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0



Download

[Request a quote](#)

[Catalog](#)

Series

Termination type	Female solder
IP rating	50
Cable Ø	5.30 - 6.50 mm
Matching parts	xxx

TECHNICAL DETAILS

Mechanics

Shell Style/Model	XA*: Straight plug, key (N) or keys (P, S and T), with black cable collet
Keying	3 key (alpha=90, plug: female contacts, receptacle: male contacts)
Housing Material	
Cable Fixing	∅ 5.3 - 6.5 mm
Variant	N : Black collet nut

Performance

Configuration	M22 : 22 Low Voltage
Insulator	L: PEEK
Rated Current	

Specifications


Test voltage (kV rms) Contact-contact:	0.6
Air clearance min. (mm) or Creepage distance min. (mm):	0.4

Others

F ret (average):	130 N
Working temperature:	-50 deg C to + 170 deg C
IP Rating:	50

DRAWINGS

Draws

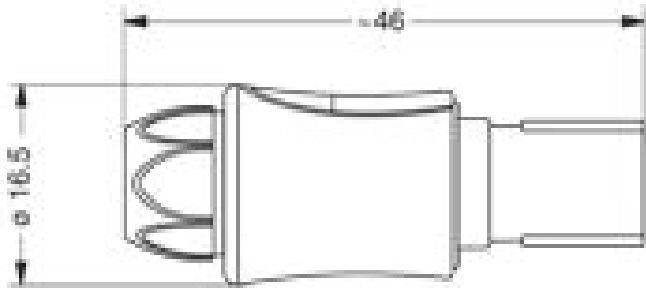

Dimensions

	A	L
mm.	16.5	46
in.	0.65	1.81

RECOMMENDED BY LEMO

Tools

None

Cables

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[XAT.M22.GLL.6N](#)