

SUMMARY

Wires

Low	6
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0

Series	1V
Termination type	Male solder
IP rating	68
Cable Ø	4.60 - 5.00 mm
Matching parts	EVP.1V.306.CLL
Status	active
Alternative part	



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FVN*: Straight plug, cable collet
Keying	
Housing Material	Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces
Cable Fixing	C50: 4.6 - 5 mm
Variant	
Weight	31.29 g

Performance

Configuration	
Insulator	
Rated Current	7 Amps

Specifications

Contact Type: Solder	
Max. Matings: 5000	
Contact Dia.: 0.7 mm (0.028in)	

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Bucket Dia.: 0.6 mm (0.024in)
 Max. Solid Conductor: 0.25 mm² (AWG 24)
 Max. Stranded Conductor: 0.14 mm² (AWG 26)
 R (max): 6.1 mOhm
 Vtest: 1500 V (AC), 2100 V (DC)

Others

Pressure: 30 bars
 IP Rating: 68

DRAWINGS

Draws

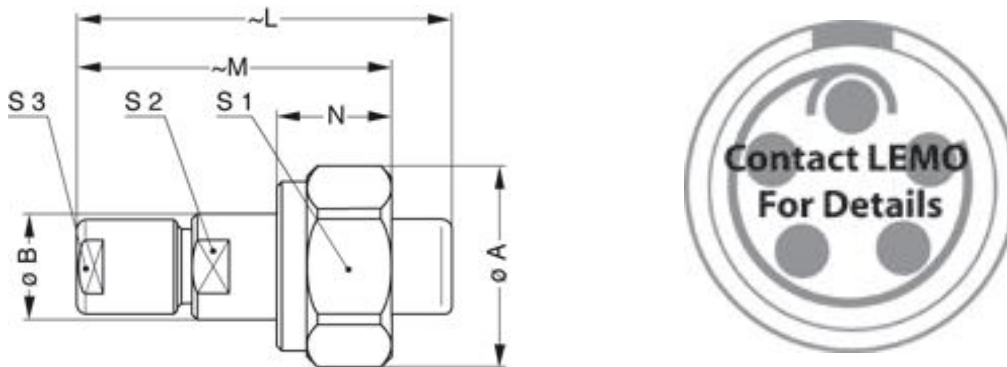

Dimensions

	A	B	L	M	N	S1	S2	S3
mm.	19.3	12	43	35	14	18	10	9
in.	0,76	0,47	1,69	1,38	0,55	0,71	0,39	0,35

 
RECOMMENDED BY LEMO

Tools

None

Cables

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

006 280	PVC	Black	
160 140	PVC	Grey	

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[FVN.1V.306.CLAC50](#)