

SUMMARY

Wires

Low	0
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

Series	SP
Termination type	
IP rating	50
Cable Ø	6.60 - 7.50 mm
Matching parts	
Status	active
Alternative part	

TECHNICAL DETAILS

Mechanics

Shell Style/Model	SA*: Straight plug, key (N) or keys (P, S and T), with black cable collet
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Housing Material	Proprietary sulfone, black
Cable Fixing	∅ 6.6 - 7.5 mm
Variant	NZ : Black collet nut for bend relief
Weight	6.02 g

Performance

Configuration	
Insulator	
Rated Current	4.0 Amps

Specifications

Test voltage (kV rms) Contact-contact:	1.05
Air clearance min. (mm) or Creepage distance min. (mm):	0.50


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Others

IP Rating: 50

DRAWINGS

Draws

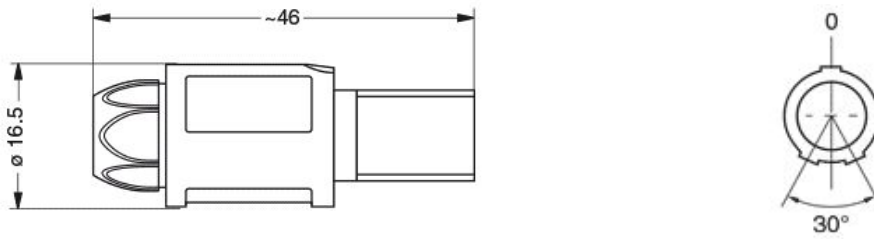

Dimensions

	A	L
mm.	16.5	46
in.	0,65	1,81

RECOMMENDED BY LEMO

Tools

None

Cables

150 222			
160 222			

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[SAN.M13.NLA.7NZ](#)