

SUMMARY

Wires

Low voltage	2
High voltage	2
Fiber optic	2

Series	3K
Termination type	Hybrid contacts
IP rating	68 when mated
AWG wire size	24.00 - 20.00
Cable Ø	8.90 - 9.50 mm
Status	active
Matching parts	FUW.3K.93C.YSEC96



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	PU*: Free receptacle, 'Y' design, cable collet adapter and long shell for fitting a bend relief with cap (with enhanced screen efficiency)
Keying	5 keys (alpha=95, beta=115, gamma=20, delta=30, plug: female LV, male HV, female FO contacts)
Housing Material	Special housing (see notes for details)
Weight	87.82 g

Performance

Configuration	3K.93C : 2 FO Type F2, 2 HV + 2 LV
Insulator	
Rated Current	10 Amps

Specifications


Fiber Optic Contact: Type F2
Vtest power/signal (AC): 2250V , 1000V
Working voltage power/signal(AC): 600V , 42V
Cable type: SMPTE 311M or EBU R100

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Endurance (Shell): 20000 mating cycles
Temp (min / max): -40°C / +80°C
Humidity (max): <=95% [at 60 deg C / 140 F]
Vibration: 15 g [10 Hz - 2000 Hz]
Shock Resistance: 100 g [6 ms]
Climatical Category: 50/175/21
Shielding (min): 95 dB (10 MHz)
Shielding (min): 80 dB (1 GHz)

DRAWINGS

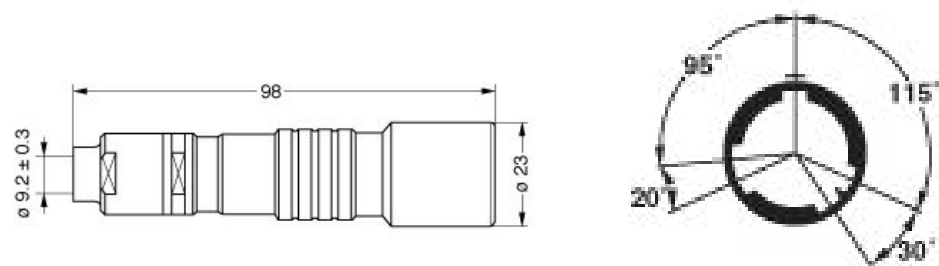

Dimensions

	A	L
mm.	23	98
in.	0,91	3,86

RECOMMENDED BY LEMO

Tools

- Crimp settings: AWG/Selector = 20-22-24 14-16-18/6-5-5 7-6-5
- Positionner: [DCE.91.093.BVC](#)
- Positionner 2: [DCE.91.133.BVCM](#)
- Extractor: [DCC.09.05B.LAG](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Extractor 2:	DCC.13.15B.LAG
Fiber Tool:	WST.KI.125.34
Fiber Tool 2:	DCB.91.119.0TN
Replacement contact:	FGG.3B.560.ZZC / EGW.3K.666.ZZM
Spanner wrench:	DCD.3E.ZZZ.PA150

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[PUW.3K.93C.YSEC96](#)