

## SUMMARY

### # Wires

Low voltage	4
Coax	4



Image is for illustrative purpose only

Series	0R
Termination type	Female crimp
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	1.60 - 6.20 mm
Status	active
Matching parts	<a href="#">FGG.0R.804.GLC4162</a>

### Download

- [Request a quote](#)
- [Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	PHG*: Free receptacle, cable collet key (G) or key (A), with cable collet
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	11.03 g

### Performance

Configuration	0R.804 : 4 Coax (50 Ohm), 4 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	2.0 Amps

### Specifications


Impedance:	50
Test Voltage (kV rms):	1.35

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

---

# DRAWINGS

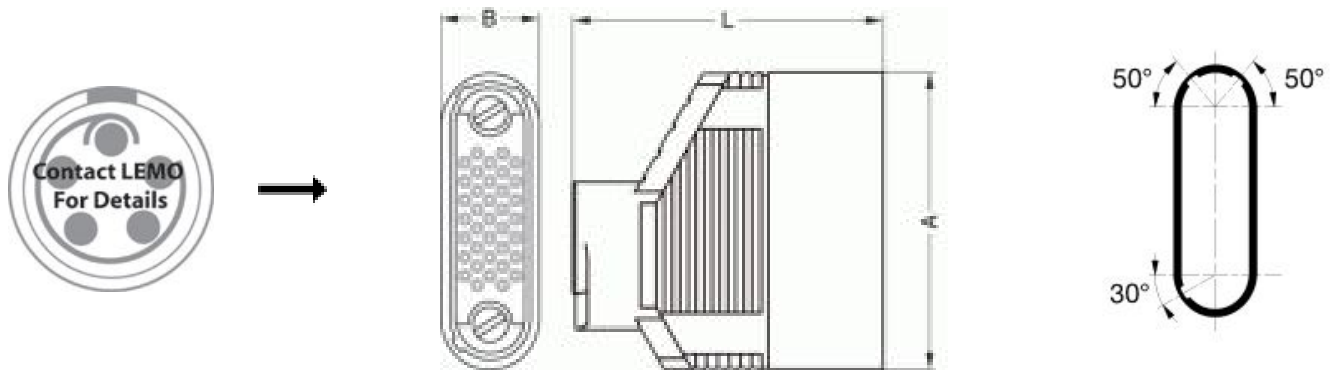

---

# RECOMMENDED BY LEMO

## Tools

Crimp Tool:	<a href="#">DPC.91.701.V</a>
Crimp Tool 2:	<a href="#">DPE.99.003.1K</a>
Crimp settings:	AWG/Selector = 22-24-26/6-5-5
Positionner:	<a href="#">DCE.91.070.BVM</a>
Replacement contact:	EGG.0B.655.ZZM

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[PHG.0R.804.GLM4162](#)