

SUMMARY

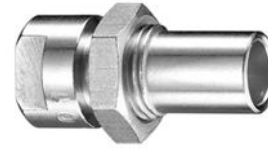


Image is for illustrative purpose only

Wires

Coax 1

Series 01
Termination type Coupler/adapter/bridge
IP rating 50
AWG wire size 0.00 - 0.00
Cable Ø 0.00 - 0.00 mm
Status active

Download

[Request a quote](#)
[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model RAD.01*: Fixed coupler, nut fixing
Keying Circular, flange side: female contacts, other side: female contacts
Housing Material Brass (gold plated [ISO 27874]) shell, collet nut, brass latch sleeve and mid pieces
Weight 1.79 g


Performance

Configuration 01.250 : 1 Coax (50 Ohm)
Insulator
Rated Current

Others

Endurance (Shell): 1000 mating cycles

DRAWINGS

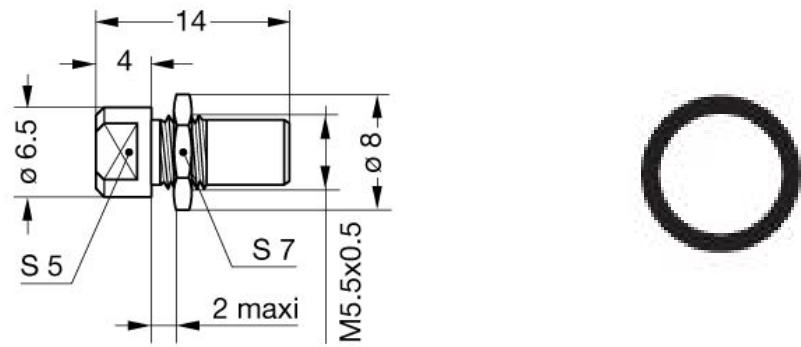

Dimensions

	A	B	E _{max}	L	M	S1	S2	e1
mm.	6.5	8	2	14	4	5	7	M5x0.5
in.	0,26	0,31	0,08	0,55	0,16	0,20	0,28	

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[RAD.01.250.DLM](#)