

SUMMARY

Wires

Low voltage 4



Image is for illustrative purpose only

| | |
|------------------|--------------------------------|
| Series | SP |
| Termination type | Male solder |
| IP rating | 50 |
| AWG wire size | 26.00 - 22.00 |
| Cable Ø | 4.00 - 5.20 mm |
| Status | active |
| Matching parts | SRN.M04.GLL.5G |

Download

[Request a quote](#)

[Eplan](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

| | |
|-------------------|--|
| Shell Style/Model | SA*: Straight plug, key (N) or keys (P, S and T), with grey cable collet |
| Keying | 3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts) |
| Housing Material | Proprietary sulfone, gray |
| Variant | G : Gray collet nut |
| Weight | 5.29 g |

Performance

| | |
|---------------|---------------------------|
| Configuration | SP.M04 : 4 Low V. |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated Current | 11.5 Amps |

Specifications

Contact Type: Solder
Contact Dia.: 1.3 mm (0.0512in)
Bucket Dia.: 1.1 mm (0.04in)
Min. Conductor: 0.36 mm² (AWG 22)
Max. Conductor: 1 mm² (AWG 18)
Test voltage (kV rms) Contact-contact: 1.60
Air clearance min.: 0.96 mm

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Creepage distance min.: 0.96 mm

Others

Endurance (Shell): >2000 mating cycles

Temp (min / max): -50°C / +170°C

DRAWINGS

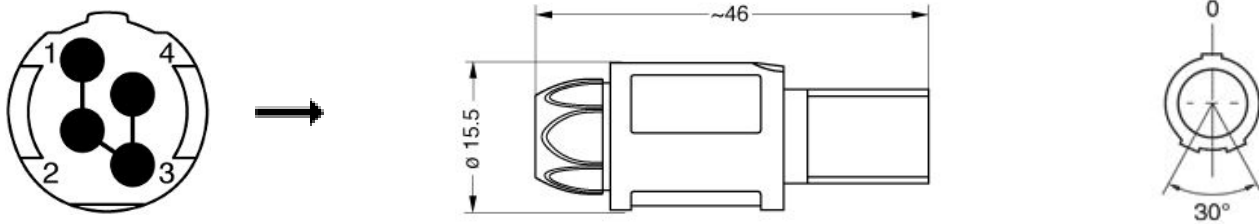

Dimensions

| | A | L |
|-----|------|------|
| mm. | 15.5 | 46 |
| in. | 0,61 | 1,81 |

RECOMMENDED BY LEMO



Tools

Crimp Tool: [DPC.91.701.V](#)

Cables

| | | | |
|--------------------|---------------|------|--|
| CMN.04.T22.047QGC | TPR | Grey | |
| CMN.04.T22.048QGZE | TPR (medical) | Grey | |

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

| | | | |
|--------|-----|-------|---|
| 140240 | PVC | Black |  |
| 140250 | PVC | Grey |  |
| 40140 | PVC | Black |  |
| 40260 | PVC | Black |  |
| 4080 | PVC | Grey | |
| 4221 | PVC | Black |  |
| 4280 | PVC | Black |  |
| 80080 | PVC | Grey | |
| 80082 | PVC | Red | |
| 80084 | PVC | Black | |

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[SAN.M04.GLA.5G](#)