

SUMMARY

Wires

Low voltage 6



Image is for illustrative purpose only

Series	SP
Termination type	Male crimp
IP rating	50
AWG wire size	26.00 - 22.00
Cable Ø	4.00 - 5.20 mm
Status	active
Matching parts	SRN.M06.GLM.5GZ

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	SA/Z*: Straight plug, key (N) or keys (P, S and T), with cable collet and nut for fitting a bend relief
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Housing Material	Proprietary sulfone, gray
Variant	GZ : Gray collet nut for bend relief

Performance

Configuration	SP.M06 : 6 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	8.5 Amps

Specifications

Contact Type: Crimp
Contact Dia.: 1.3 mm (0.0512in)
Bucket Dia.: 1.4 mm (0.055in)
Min. Conductor: 0.36 mm² (AWG 22)
Max. Conductor: 1 mm² (AWG 18)
Test voltage (kV rms) Contact-contact: 1.90
Air clearance min.: 1.5 mm
Creepage distance min.: 1.5 mm


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Others

Endurance (Shell): >2000 mating cycles

Temp (min / max): -50°C / +170°C

DRAWINGS

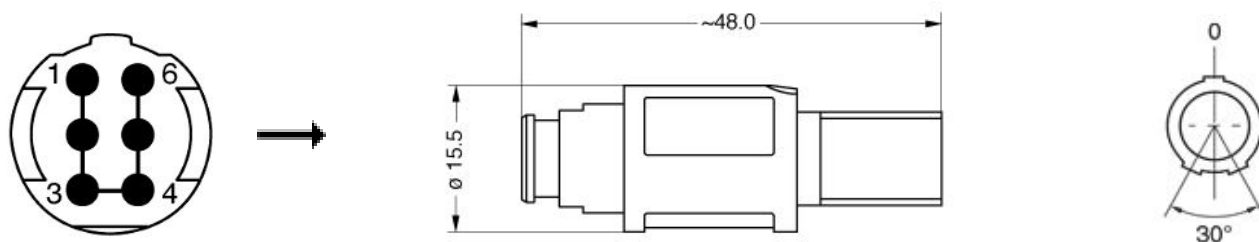

Dimensions

	A	L
mm.	15.5	48
in.	0,61	1,89








RECOMMENDED BY LEMO

Tools

Crimp Tool:	DPC.91.701.V
Crimp settings:	AWG/Selector = 20-22-24/6-5-5
Positionner:	SOE.090.VC
Replacement contact:	SAN.535.ZZC

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

CMN.06.T28.042QBCE	TPR (medical)		
CMN.06.T28.044PGZE		Grey	
CMN.06.T28.044PNZE			
106240	PTFE	White	
160140	PVC	Grey	
160260	PVC	Black	
60260	PTFE	White	
6280	PVC	Black	

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[SAN.M06.GLC.5GZ](#)