

## SUMMARY

### # Wires

Low voltage 18



*Image is for illustrative purpose only*

Series SP  
Termination type Male solder  
IP rating 50  
AWG wire size 36.00 - 28.00  
Cable Ø 5.30 - 6.50 mm  
Status active  
Matching parts [SLN.M18.GLLA](#)

### Download

[Request a quote](#)  
[Eplan](#)  
[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model SA/Z\*: Straight plug, key (N) or keys (P, S and T), with cable collet and nut for fitting a bend relief  
Keying 3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)  
Housing Material Proprietary sulfone, gray  
Variant A : Blue collet nut  
Weight 7.80 g

### Performance

Configuration SP.M18 : 18 Low V.  
Insulator L: PEEK (UL 94 / V-0/1.5)  
Rated Current 2.5 Amps

### Specifications

Contact Type: Solder  
Contact Dia.: 0.5 mm (0.0196in)  
Bucket Dia.: 0.45 mm (0.0177in)  
Max. Solid Conductor: 0.12 mm<sup>2</sup> (AWG 28)  
Max. Stranded Conductor: 0.12 mm<sup>2</sup> (AWG 28)  
R (max): 8.5 mOhm

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*


Test voltage (kV rms) Contact-contact: 0.75  
Air clearance min.: 0.47 mm  
Creepage distance min.: 0.47 mm

## Others

Endurance (Shell): >2000 mating cycles  
Temp (min / max): -50°C / +170°C

---

## DRAWINGS

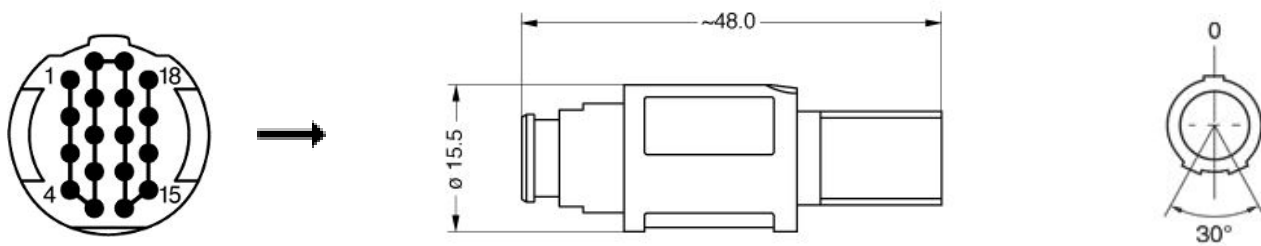

## Dimensions

	A	L
mm.	15.5	48
in.	0,61	1,89

---

## RECOMMENDED BY LEMO

## Tools

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[SAN.M18.GLA.6AZ](#)