

## SUMMARY

### # Wires

Low voltage 22



*Image is for illustrative purpose only*

Series SP  
Termination type Male solder  
IP rating 50  
AWG wire size 36.00 - 28.00  
Cable Ø 5.30 - 6.50 mm  
Status active

### Download

[Request a quote](#)

[Eplan](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model SA\*: Straight plug, key (N) or keys (P, S and T), with white cable collet  
Keying 3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)  
Housing Material Proprietary sulfone, white  
Variant B : White collet nut  
Weight 8.56 g

### Performance

Configuration SP.M22 : 22 Low V.  
Insulator L: PEEK (UL 94 / V-0/1.5)  
Rated Current 2.0 Amps

### Specifications

Contact Type: Solder  
Contact Dia.: 0.5 mm (0.0196in)  
Bucket Dia.: 0.45 mm (0.0177in)  
Max. Solid Conductor: 0.12 mm<sup>2</sup> (AWG 28)  
Max. Stranded Conductor: 0.12 mm<sup>2</sup> (AWG 28)  
R (max): 8.5 mOhm  
Test voltage (kV rms) Contact-contact: 0.60

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*


Air clearance min.: 0.48 mm  
Creepage distance min.: 0.48 mm

## Others

Endurance (Shell): >2000 mating cycles  
Temp (min / max): -50°C / +170°C

---

## DRAWINGS

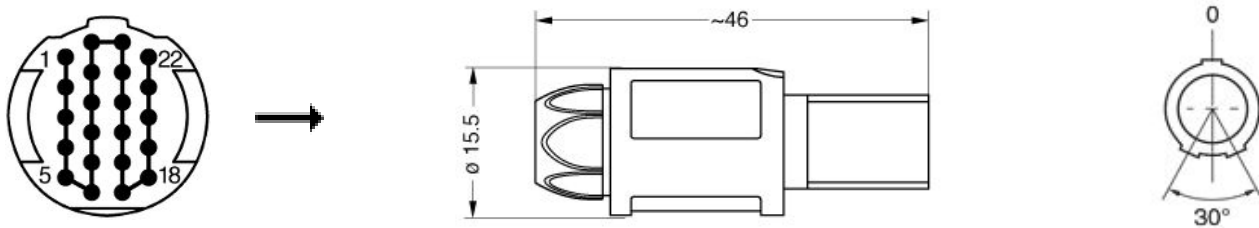

## Dimensions

	A	L
mm.	15.5	46
in.	0,61	1,81

---

## RECOMMENDED BY LEMO

### Tools

Crimp Tool: [DPC.91.701.V](#)

### Cables

CMN.22.T30.054QGZE	TPR (medical)	Grey	
--------------------	---------------	------	---------------------------------------------------------------------------------------

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[SAN.M22.BLA.6B](#)