


PCB MOUNT FUSE HOLDER FOR MINI® STYLE BLADE FUSE

125Vdc

RoHS

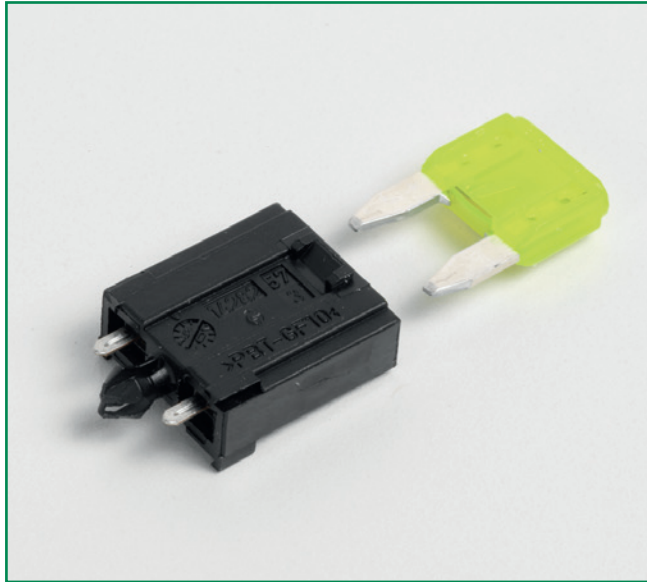

Specifications

Max Voltage Rating:	125V
Max Current Rating:	30A
Connections:	Leaf spring connector system
Body Material:	Thermoplastic UL 94-V0, heat-resistant
Clip Material:	Copper alloy, Tin-plated finish


Ordering Information

PART NUMBER	PACKAGE SIZE
178.6764.0001	100

Description

Fuse holder for MINI/ FK1 fuses for PCB applications. The FL1 Fuse Holder can be mounted in a row of nearly any number. The terminals fit into a 7.62 mm pitch.

Dimensions in mm

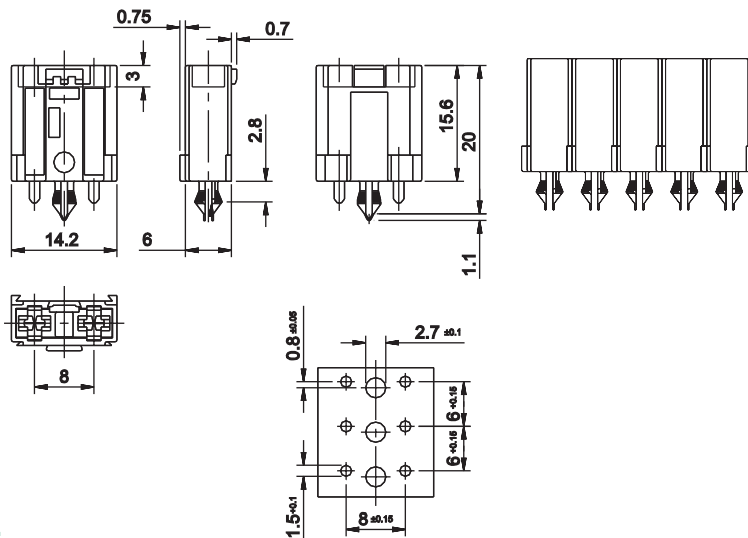

Ratings

Part Number	Description	Contact Temperature
178.6764.0001	Complete	max. 130°C

The FL1 Fuse Holder can be mounted in a row in nearly any number. The terminals of the holder will also fit into a 7.62 mm pitch.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Littelfuse:](#)

[178.6764.0001](#)