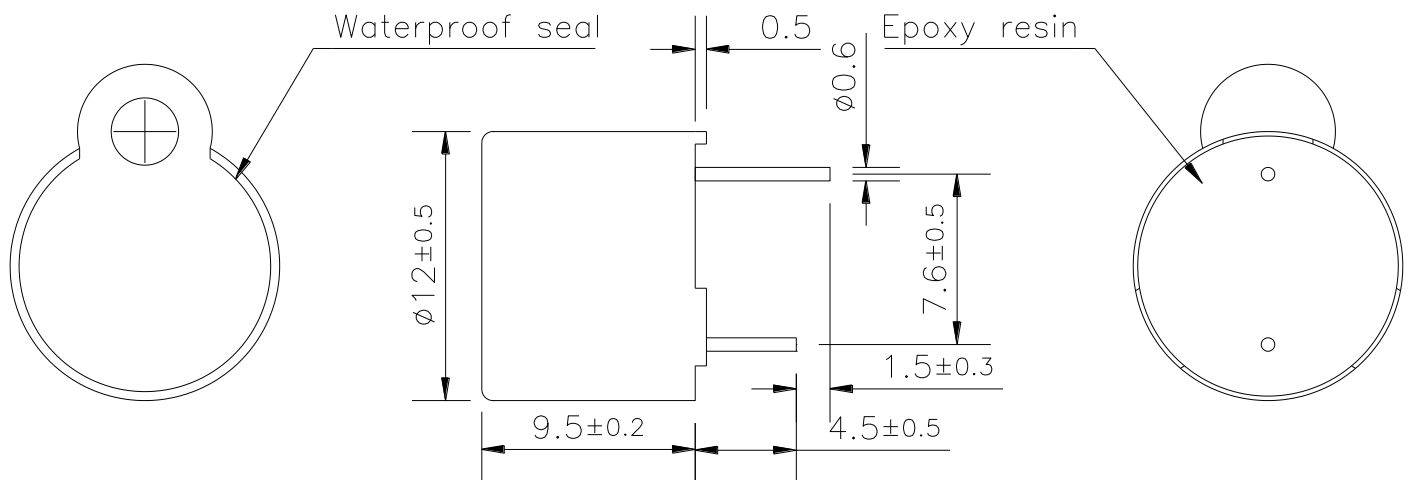


May not be suitable for all medical and aerospace applications.
Specifications: Contact Mallory Sonalert to discuss your application.

Oscillation Frequency (Hz)	2300 \pm 400
Operating Voltage (Vdc)	1.25 ~ 2.5
Rated Voltage (Vdc)	1.5
Current Consumption Max. (mA)	25 at Rated Voltage
Sound Pressure Level Min. (dB)	80 at 10cm at Rated Voltage
Tone/Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	PPO plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	1.8
Options	For other options contact factory

Dimensions: (units: mm)**ROHS Compliant****Packaging:**

Parts are supplied in tube (40 per tube).

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-12N23P-01Q](#)