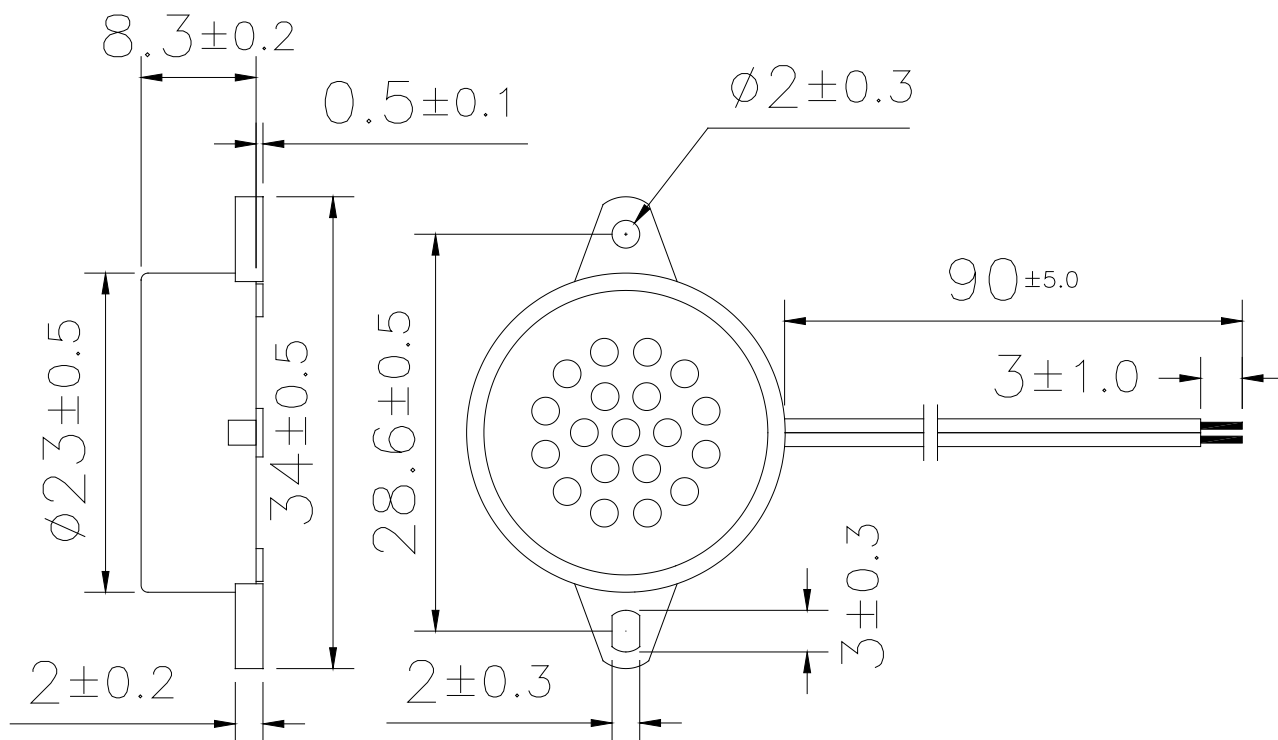


Sales Outline Drawing

**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

NO CIRCUITRY

Oscillation Frequency (Hz)	1500 ± 200
Operating Voltage (Vp-p)	2.0 ~ 5.0
Rated Voltage (Vp-p)	3.0
Input Watt (W/max)	0.15
Sound Pressure Level (dB/min)	75 at 10cm at Rated Voltage
Coil Resistance (Ω)	8.0 ± 2
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	PPO plastic resin (Color: Black)
Lead Wire	28 AWG
Weight (Grams)	3.4
Options	For other options contact factory

Dimensions: (units: mm)**PS: Vp-p = 1/2duty, square wave****ROHS Compliant**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-2015WQ](#)