


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Impedance (Ω)	$8 \pm 15\%$ at 1000 Hz 1.0 V
Rated Power (W)	2.0
Max Power (W)	2.5
Resonance Freq Fo (Hz)	$670 \pm 20\%$
Frequency Range (Hz)	Fo ~ 10000
Output S.P.L. (dB)	98 ± 3 at 2.0w/.1m 0.8k, 1.0k, 1.2k, 1.5kHZ 75 ± 3 at 1w/1m 0.8k, 1.0k, 1.2k, 1.5kHZ
Magnet	Nd-Fe-B
Frame Material	ABS 777D
Operating / Storage Temp	-20 to 55°C/ -30 to 65°C
Weight (g)	4.53
Options	For other options contact factory

Dimensions: ± 0.2 (units: mm)

ROHS Compliant

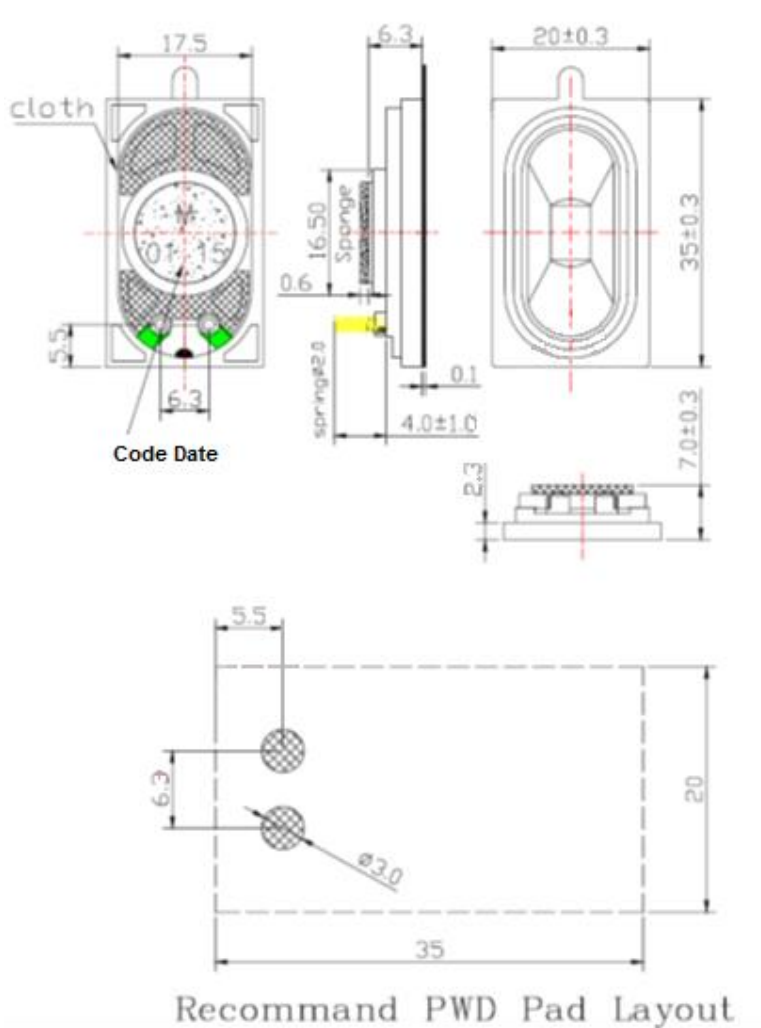

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PSR3520F08S7K](#)