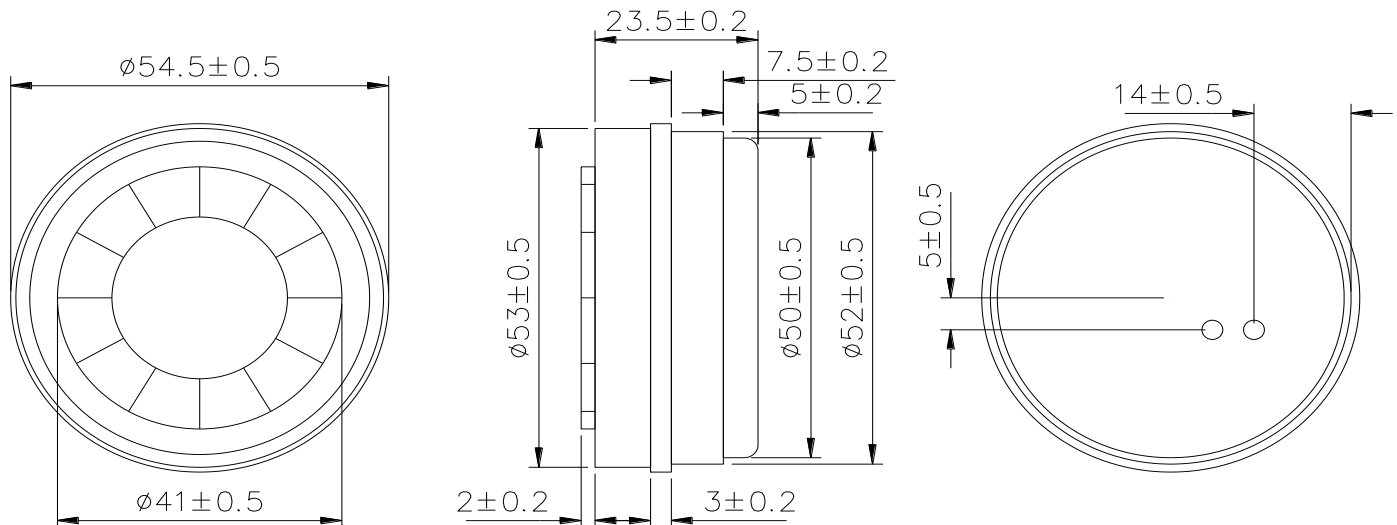


**May not be suitable for all medical and aerospace applications.**

**Specifications: Contact Mallory Sonalert to discuss your application.**

Resonant Frequency (Hz)	3500 ± 500
Operating Voltage (V <sub>p-p</sub> /max)	150
Rated Voltage (V <sub>p-p</sub> )	5.0 / 125
Current Consumption (mA/max)	4.0 / 47
Sound Pressure Level (dB/min)	90 @ 30cm / 105 @ 100cm
Capacitance (pF)	30,000 ±30% at 120Hz
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 UL94HB plastic resin (Color: Red / White / Black)
Lead Wire	2 Solder Pads
Weight (Grams)	31
Options	For other options contact factory

**NO CIRCUITRY****Dimensions:** (units: mm)PS: V<sub>p-p</sub> = 1/2duty, square wave**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PT-593SQ](#)