



**Mallory Sonalert Products, Inc.**

Part #:

**SBS12XHFL**

**Sales Outline Drawing**

Revision:

**A**



<b>Specifications:</b>	<b>cUL Recognized to IEC60601-1-8 Oxygen Melody - High Priority Only</b>
Sound Level Category:	Extra Loud
Mode of Operation:	High Priority Alarm - 10 beeps repeating every 2.5 sec
Voltage Rating:	9 to 12 VDC
Frequency:	150 to 4000 Hz
Loudness @ 10cm:	95 to 105 dB(A) Typ.
Average Current Draw:	<300mA Typ.
l <sub>pk</sub> Current*:	400mA
Housing Material:	ABS 777D Plastic Resin, Black
Storage Temperature:	-40° to +85° C
Operating Temperature:	-30° to +65° C
Weight Typical:	1.1 oz (32g)
Options:	Please contact factory.

**Dimensions:** Inches (mm) **cUL Recognized** **ROHS Compliant**

PATENT NUMBER: 7880593

Before Code Date: 1546 Not cUL Recognized

After Code Date: 1547 cUL Recognized

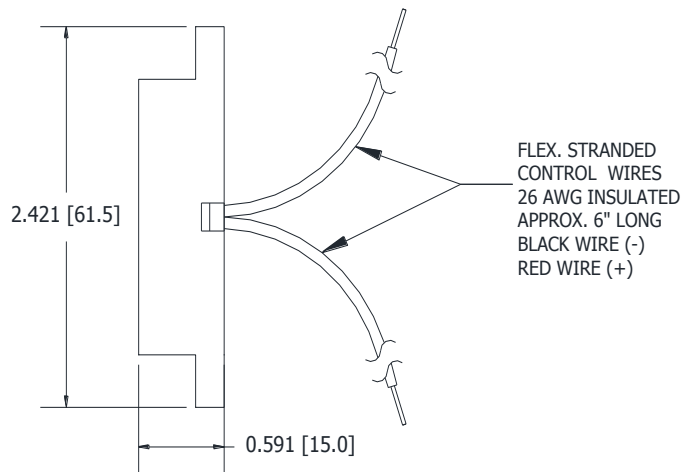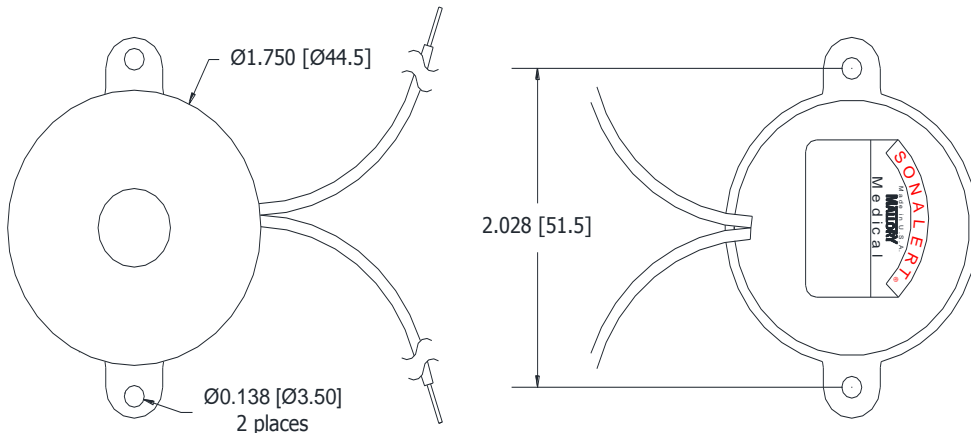

\*l<sub>pk</sub> = Instantaneous Peak

tolerances: ±0.01 [±0.3]  
±0.005 [±0.1]

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SBS12XHFL](#)