

**Mallory Sonalert Products, Inc.**Part #: **ZT028LDFP1R30****Sales Outline Drawing**Revision: **C****Specifications:**



|                       |   |
|-----------------------|---|
| Sound Level Category  | Loud  |
| Mode of Operation     | Fast Pulse @ 10 PPS for 30 Seconds, then Flashing Light until reset.          |
| Lens Color            | Opaque White  |
| LED Color             | RED   |
| LED Mode of Operation | FLASH 10PPS   |
| Voltage Rating        | 20 to 28 VDC  |
| Frequency             | 3900 $\pm$ 500 Hz   |
| Loudness @ 2 FT       | 85 to 95 dB(A) Typ.   |
| Current Draw          | 40mA MAX  |
| Housing Material      | 6/6 Nylon, Color: Black   |
| Front Cap Material    | 6/6 Nylon, Color: Opaque White  |
| Storage Temperature   | -40° to +80° C  |
| Operating Temperature | -30° to +65° C  |
| Panel Mounting        | Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole. |
| Knurled Nut           | Used to attach part to panel. The max recommended torque is 10 in-lbs.        |
| Weight (Typical)      | 28 g  |
| NEMA 3R, 4X, & 12     | Approved with use of included gasket.   |
| Options               | Please contact factory.   |

**Dimensions:** Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER

9165440

9576442

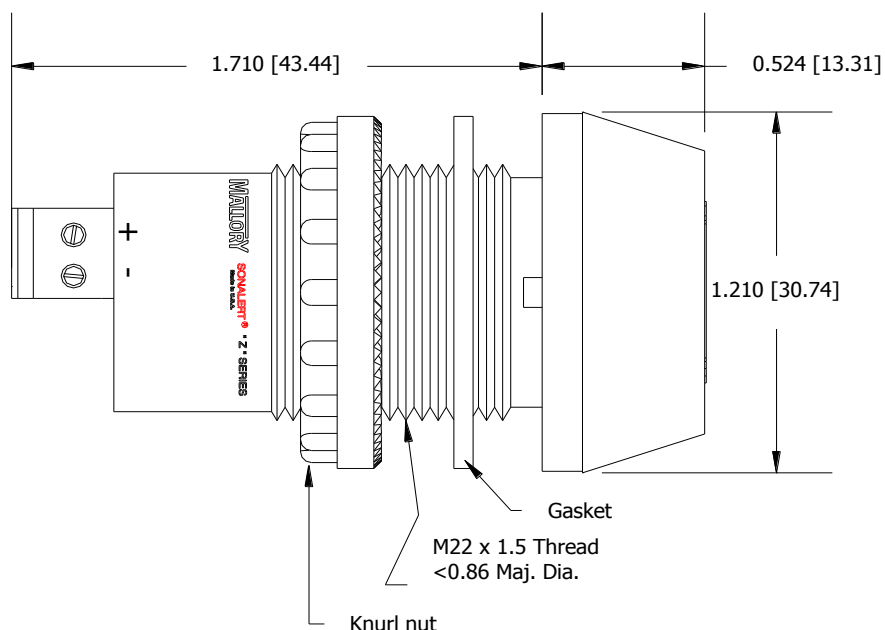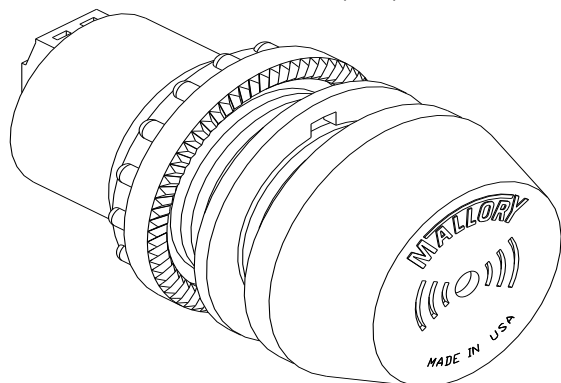

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT028LDFP1R30](#)