

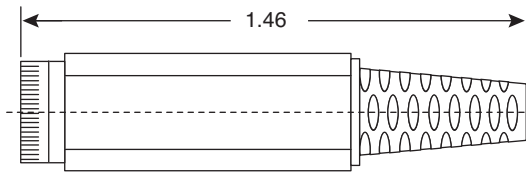


# 3.5mm In-Line Jack


 
16PJ106-EX

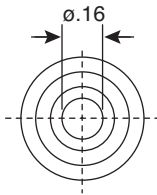

3.5mm In-Line Jack

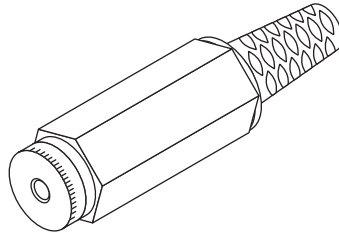

Circuit Diagram

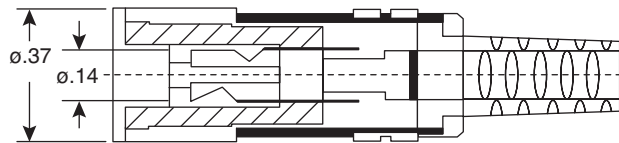

Dimensions: In.

SPECIFICATIONS	
Type:	3.5mm In-Lin
Color:	Black
Insulation Resistance:	100M $\Omega$ min. @ 250VDC
Breakdown Voltage:	250VAC for 1 Minute
Metal:	Nickel Plated Brass
Body:	Polyphenylenoxide
Terminal A:	Gold Plated Phosphor Bronze
Terminal B:	Nickel Plated Phosphor Bronze
Terminal C:	Nickel Plated Steel
Cap:	Polyethylene
RoHS Compliant by Exemption	

Date Last Revised: 12-2-05

Available from Mouser Electronics  
1-800-346-6873  
www.mouser.com

KC-300827

16PJ106-EX

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[16PJ106-EX](#)