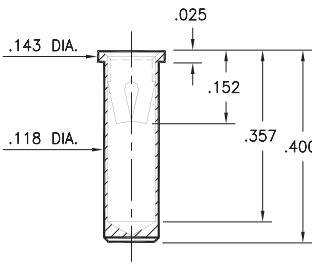
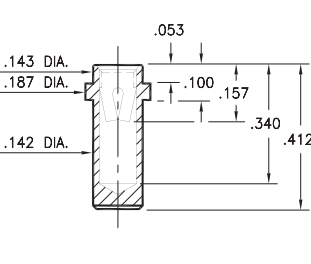
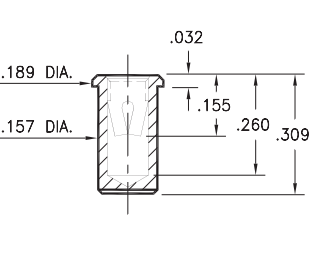
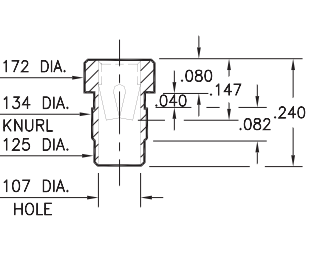
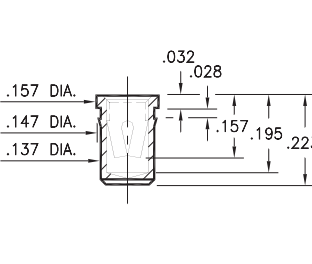
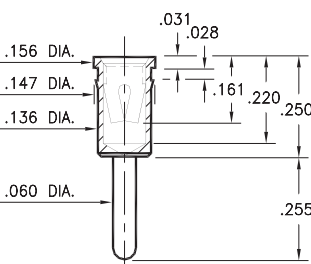
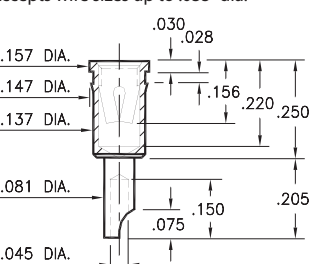
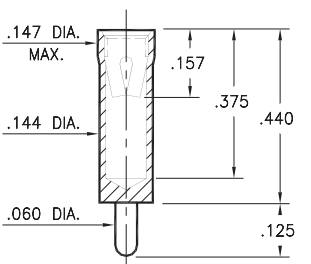
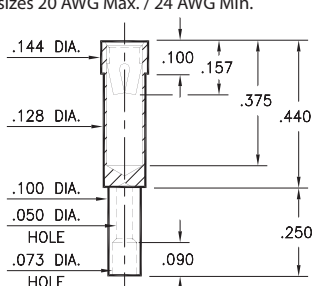
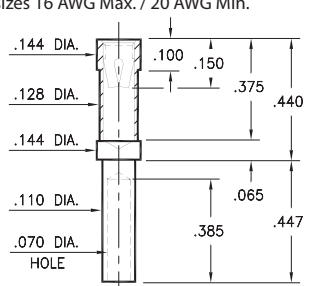
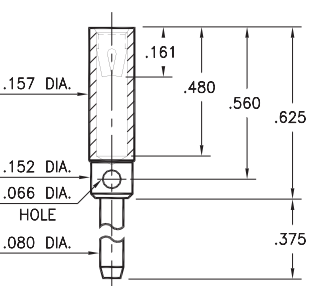
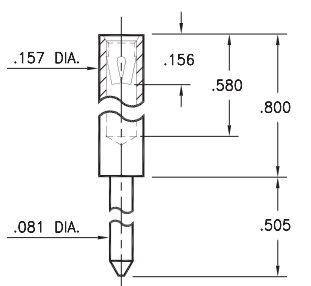


# PIN RECEPTACLES

FOR .065" - .082" DIAMETER PINS

<p><b>0394</b> 0394-0-15-XX-07-XX-10-0 Solder mount in .120 min. mounting hole</p> 	<p><b>0393</b> 0393-0-15-XX-07-XX-10-0 Solder mount in .144 min. mounting hole</p> 	<p><b>0391</b> 0391-0-15-XX-07-XX-10-0 Solder mount in .159 min. mounting hole</p> 	<p><b>9016</b> 9016-0-15-XX-07-XX-10-0 Press-fit in .131 mounting hole</p> 
<p><b>0493</b> 0493-0-15-XX-07-XX-10-0 Press-fit in .144 mounting hole</p> 	<p><b>0490</b> 0490-0-15-XX-07-XX-04-0 Press-fit in .144 mounting hole</p> 	<p><b>0616</b> 0616-0-18-XX-07-XX-10-0 Press-fit in .144 mounting hole Accepts wire sizes up to .035" dia.</p> 	<p><b>0387</b> 0387-0-15-XX-07-XX-04-0 Solder mount in .063 min. mounting hole</p> 
<p><b>0370</b> 0370-0-19-XX-07-XX-10-0 Wire crimp termination. Accepts wire sizes 20 AWG Max. / 24 AWG Min.</p> 	<p><b>4040</b> 4040-0-19-XX-07-XX-10-0 Wire crimp termination. Accepts wire sizes 16 AWG Max. / 20 AWG Min.</p> 	<p><b>0491</b> 0491-0-19-XX-07-XX-04-0 For horizontal wire termination</p> 	<p><b>9214</b> 9214-0-15-XX-07-XX-10-0 Solder mount in .083 min. mounting hole</p> 

## SPECIFICATIONS:

**Shell Material:** Brass Alloy 360, 1/2 Hard

**Contact Material:** Beryllium Copper Alloy 172, HT

**Dimensions:** Inches

**Tolerances On:** Lengths: ±.005

Diameters: ±.002

Angles: ± 2°



**ORDER CODE:** XXXX - X - 1X - XX - 07 - XX - XX - 0

**BASIC PART #**

**SPECIFY SHELL FINISH:**

- 01 200 μ" TIN/LEAD OVER NICKEL
- ◆ 80 200 μ" TIN OVER NICKEL (RoHS)
- ◆ 15 10 μ" GOLD OVER NICKEL (RoHS)

**SPECIFY CONTACT FINISH:**

- 01 200 μ" TIN/LEAD OVER NICKEL
- ◆ 80 200 μ" TIN OVER NICKEL (RoHS)
- ◆ 27 30 μ" GOLD OVER NICKEL (RoHS)

**SELECT CONTACT:**

**#07 CONTACT (DATA ON PAGE 261)**

(For alternate contact choices, see group H on page 248)



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mill-Max:](#)

[0370-0-19-80-07-27-10-0](#) [0391-0-15-01-07-14-10-0](#) [9214-0-15-80-07-80-10-0](#) [9016-0-15-80-07-27-10-0](#) [0370-0-19-15-07-27-10-0](#) [0391-0-15-15-07-27-10-0](#) [0391-0-15-15-07-14-10-0](#)