

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009503121

Status:

Active

Overview:

[KK Interconnect Solutions](#)

Description:

KK 3.96mm Crimp Terminal Housing, Friction Ramp, 12 Circuits, Natural

Documents:

[3D Model](#)


[3D Model \(PDF\)](#)

[Drawing \(PDF\)](#)

[Product Specification PS-08-50-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
Overview	KK Interconnect Solutions
Product Name	KK 396
UPC	800753616301
Physical	
Circuits (maximum)	12
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	3.088/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	See Product Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	2139-12A
Reference - Drawing Numbers	
Product Specification	PS-08-50-001
Sales Drawing	SD-2139-001, SD-2139-002

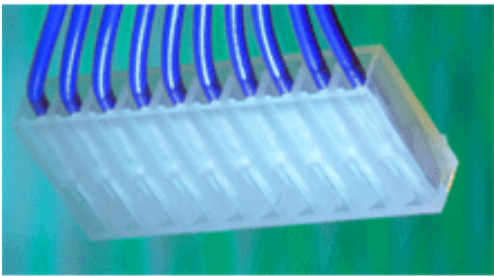

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[2139](#) Series

Mates With

KK 396 Headers: [41771](#) , [41772](#) , [41791](#) , [41792](#) , [42491](#) , [42492](#) , KK 396 Breakaway Headers: [41661](#) , [41662](#) , [41671](#) , [41672](#)

Use With

[2478](#) Crimp Terminals for 18-24 AWG, [2578](#) Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

09-50-3121