

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022552323](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Crimp Housing, Dual Row, Version C, Back Ribs, 32 Circuits, Black

Documents:

3D Model	Product Specification PS-70400-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70450-100-001 (PDF)
3D Model (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version C
Overview	SL Modular Connectors
Product Name	SL
UPC	800753778412

Physical

Breakaway	No
Circuits (maximum)	32
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	2.752/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	70450-0114
--------------------	------------

Reference - Drawing Numbers

Packaging Specification	PK-70450-100-001
Product Specification	PS-70058-001, PS-70400-001
Sales Drawing	SD-70450-0100-0125-001
Test Summary	TS-70058-001-001

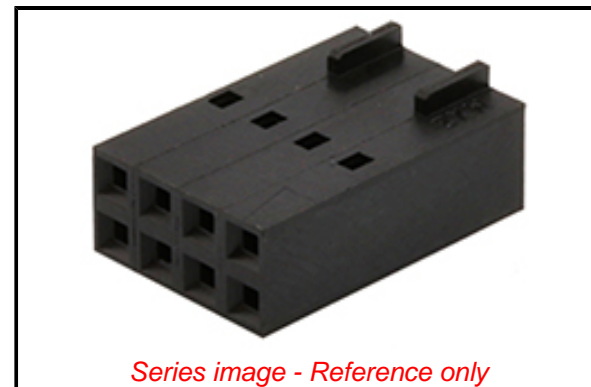

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[70450 Series](#)

Mates With

2.54mm Pitch C-Grid Header [70229](#) , [70280](#)
 , [70246](#) , [70247](#)

Use With

[70058](#) , [71851](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-55-2323](#)