

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0050842150](#)
Status: **Active**
Overview: [MLX Power Connectors](#)
Description: 2.13mm Diameter MLX Pin and Socket Receptacle, 15 Circuits, Natural

Documents:

| | |
|---|---|
| Drawing (PDF) | Packaging Specification PK-42022-XX-001 (PDF) |
| 3D Model (PDF) | Test Summary TS-42022-0001-001 (PDF) |
| 3D Model | Datasheet (PDF) |
| Product Specification PS-42022-0001-001 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|--|
| Product Family | Crimp Housings |
| Series | 42022 |
| Application | Power, Wire-to-Wire |
| Comments | Glow Wire Equivalent Part Number 366440008 . Current – Maximum per contact 20A if used with 36663 and 36664 terminal |
| Overview | MLX Power Connectors |
| Product Name | MLX |
| UPC | 800753755307 |

Physical

| | |
|-------------------------------|----------------|
| Circuits (maximum) | 15 |
| Circuits Detail | 15 |
| Color - Resin | Natural |
| Flammability | 94V-2 |
| Gender | Receptacle |
| Glow-Wire Capable | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Resin | Nylon |
| Net Weight | 10.481/g |
| Number of Rows | 3 |
| Packaging Type | Carton |
| Panel Mount | Yes |
| Pitch - Mating Interface | 6.35mm |
| Polarized to Mating Part | Yes |
| Stackable | No |
| Temperature Range - Operating | -55° to +105°C |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 20.0A |
|-------------------------------|-------|

Solder Process Data


| | |
|------------------------------|-----|
| Lead-free Process Capability | N/A |
|------------------------------|-----|

Material Info

| | |
|--------------------|-----------|
| Engineering Number | 42022-15A |
|--------------------|-----------|

Reference - Drawing Numbers

| | |
|-------------------------|-------------------|
| Packaging Specification | PK-42022-XX-001 |
| Product Specification | PS-42022-0001-001 |
| Sales Drawing | SD-42022-XX-001 |

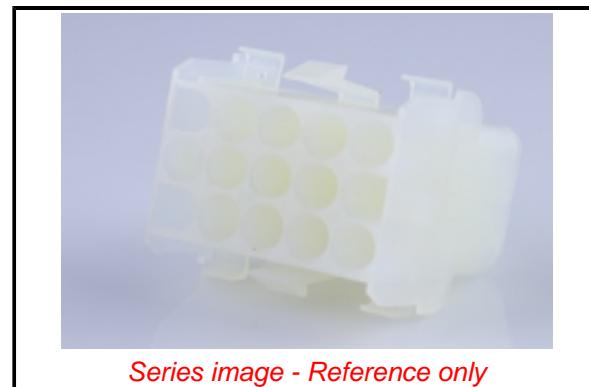

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[42022 Series](#)

Mates With

MLX Power Crimp Housing Plug [42021](#)

Use With

MLX Crimp Terminal [42023](#) , [42024](#) . MLX Male Pre-Crimped Lead [797582029](#) , [797582030](#) . MLX Female Pre-Crimped Lead [797582031](#) , [797582032](#)

This document was generated on 09/08/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[50-84-2150](#)