

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0134210018**
Status: **Active**
Overview: Asset Tracking Solutions
Description: Alien Enterprise 4-port Fixed RFID Reader with Single-Reader Management, No Additional Readers Supported, 916-928 MHz, for Uruguay and Peru

Documents:

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family RFID Products
Series 13421
Comments Includes Reader ONLY. No PoE/DC Power Supply Included.
Component Type Fixed RFID Reader
Kit Option Reader Only
LAN Protocols TCP/IP, NTP, DNS, DHCP, SNMP
Market Peru, Uruguay
More Detailed Tech Information For detailed product and compliance certification information, please https://www.alientechnology.com/download/alr-f800-x-documents/?wpdmdl=8100&ind=MTU2MjA4NjY5M3dwZG1fQUxSLUY4MDAtWCAoMjA0OC00MS00RDRONL. Alien Datasheet.

Overview

Product Name Alien
RFID Standard EPC C1 Gen 2, ISO 18000-6c
Reader Protocols ARP, LLRP
Type Enterprise w/Multi-Reader Mgmt
UPC 193264421664

Physical


Additional Readers Supported None
Antennas Up to 4 Supported
Communications LAN TCP/IP (RJ-45), RS-232 (DB-9 F), USB Console, USB Host
Dimensions 202.00 x 191.00 x 28.00mm
General Purpose I/O 4 in / 8 out (Isolated)
Memory 1 GB RAM, 2 GB Flash
Operating System Linux
Packaging Type Carton
Software SDK Java, .NET, Ruby APIs
Temperature Range - Operating -20° to +50°C

Electrical

Frequency 916-928 MHz
Max Conductive RF Power (dBm) 31.6
Power Source PoE, AC/DC Power Converter

Material Info

Engineering Number F800-URY-X0-RDRONL

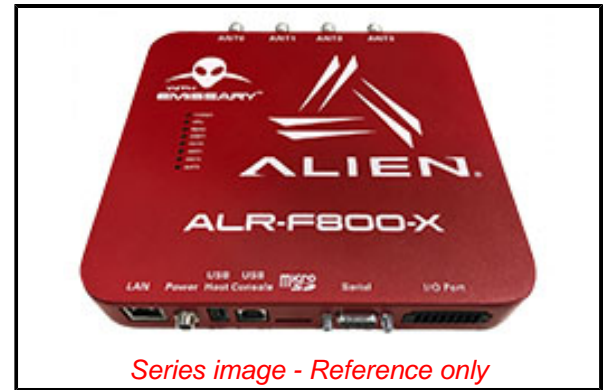

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

13421 Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[13421-0018](#)