

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150200236**
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 127.00mm Cable Length, Gold (Au) Plating, 22 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
Series 15020
Comments Contacts on opposite sides, Type D
Crimp Quality Equipment Yes
Overview FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name Premo-Flex FFC Jumper
UPC 884982176980

Physical

Cable Length 127.00mm
Circuits (Loaded) 22
Contact Layout Type D (opposite side)
Material - Plating Mating Gold
Net Weight 0.915/g
Packaging Type Bag
Pitch - Mating Interface 0.50mm
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A
Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.5A
Voltage - Maximum 60V AC

Material Info

Reference - Drawing Numbers

Product Specification PS-15020-001-001
Sales Drawing SD-15020-001-001

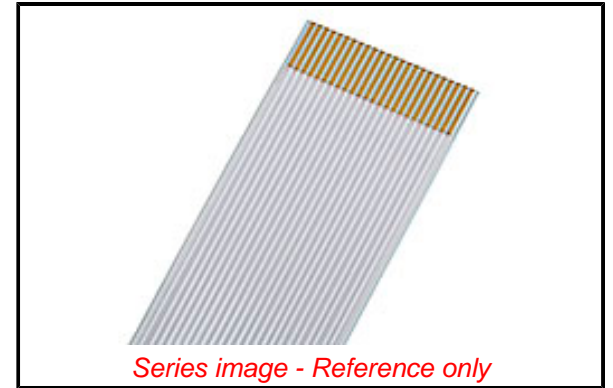

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

15020 Series

Mates With

Easy-On FFC/FPC Connector:

[5034802200](#) , [5051102291](#) , [524352271](#) ,
[524372271](#) , [5019512210](#) , [5019512230](#) ,
[5019512250](#) , [525592253](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0236](#)