

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0150200330**  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 203.00mm Cable Length, Gold (Au) Plating, 30 Circuits

**Documents:**

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)  
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family Cable  
Series 15020  
Comments Contacts on opposite sides, Type D  
Crimp Quality Equipment Yes  
Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)  
Product Name Premo-Flex FFC Jumper  
UPC 884982177925

**Physical**

Cable Length 203.00mm  
Circuits (Loaded) 30  
Contact Layout Type D (opposite side)  
Material - Plating Mating Gold  
Net Weight 1.962/g  
Packaging Type Bag  
Pitch - Mating Interface 0.50mm  
Temperature Range - Operating -40° to +105°C  
Wire Size AWG N/A  
Wire/Cable Type Flat Flex Cable


**Electrical**

Current - Maximum per Contact 0.5A  
Voltage - Maximum 60V AC

**Material Info**

**Reference - Drawing Numbers**

Product Specification PS-15020-001-001  
Sales Drawing SD-15020-001-001

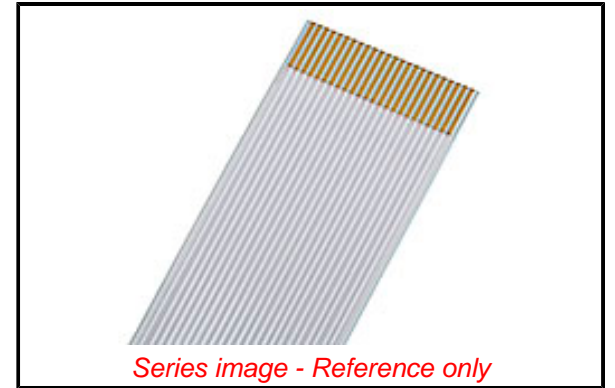

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

15020 Series

**Mates With**

Easy-On FFC/FPC Connector: <br>  
[5051103091](#) , [524353071](#) , [541043031](#) ,  
[524373071](#) , [541323062](#) , [5019513010](#) ,  
[5019513030](#) , [5019513050](#) , [525593052](#) ,  
[5034803000](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0330](#)