

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0190270301](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** ATP Perishable Tool Kit used in ATP Presses that Process Product on Tape

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<a href="#">207125</a>
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Tool Type	Pneumatic Press
UPC	756054850770
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

Engineering Number ATP

**Reference - Drawing Numbers**

Application Tooling Documents  
 ATS-190270301-001, TM-192280498-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

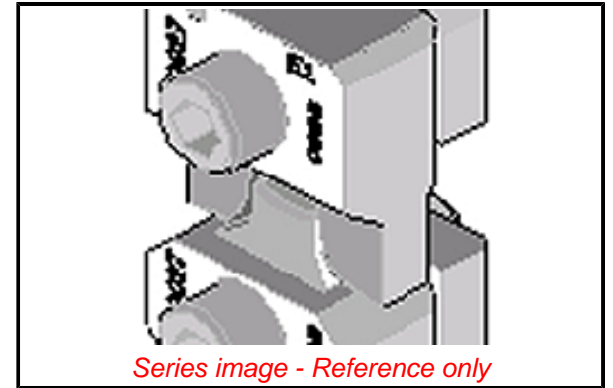

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207125 Series](#)

**Use With**

ATP-301 press, ATP-101 press, ATP-101W press, ATP-101WDI, ATP-101HD

**Application Tooling** | **FAQ**

Description	Product #
Krimptite Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire	<a href="#">190440138</a>
Krimptite Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 7/16" (M11), Length 32.51mm, Mylar Tape Carrier	<a href="#">190690146</a>
C-301-12T RING KRIMPTITE TAPE DBL SPACE	<a href="#">191930095</a>
C-301-76T RING VERSAKRIMP TAPE DBL SPACE	<a href="#">191930100</a>

This document was generated on 07/30/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19027-0301](#)